




O-obroč

O-RG 16,40x1,00/FKM 5 PIECE

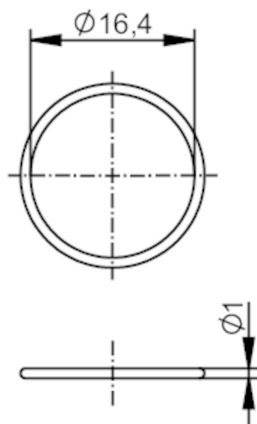

Pogoji okolja

Temperatura okolice	[°C]	-30...200
---------------------	------	-----------

Mehanski podatki

Teža	[g]	1,95
Notranji premer	[mm]	16,4
Zunanji premer	[mm]	18,4
Materiali		FKM

Opombe

Embalažna enota	5 Kosov
-----------------	---------