


O-obroč

O-RG 16,40x1,00/EPDM 5 PIECE

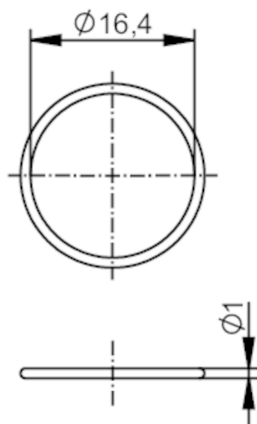

Pogoji okolja

Temperatura okolice	[°C]	-40...150
---------------------	------	-----------

Mehanski podatki

Teža	[g]	1,85
Notranji premer	[mm]	16,4
Zunanji premer	[mm]	18,4
Materiali		EPDM

Opombe

Embalažna enota	5 Kosov
-----------------	---------