


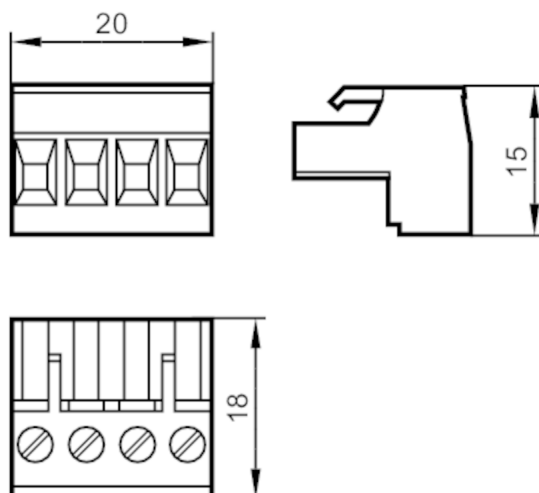

Vijačne objemke

Screw terminals / 6 pcs.



Električni podatki

Maks. obremenilni tok	[A]	20; (2,5 mm ²)
-----------------------	-----	----------------------------

Pogoji okolja

Temperatura okolice	[°C]	-30...100
---------------------	------	-----------

Mehanski podatki

Teža	[g]	41,7
------	-----	------

Materiali	deli pod tokom: bakrova zlitina pokositreno; PA	
-----------	---	--

Pritezni vrtilni moment	[Nm]	0,5
-------------------------	------	-----

Opombe

Embalážna enota	6 Kosov
-----------------	---------

Električni priključek

0,2...2,5 mm ² ; Abisolierlänge: 7 mm
--