


Adapter antene RFID za povečanje hitrosti pomikanja

ANT-AMP/490x40/KQ

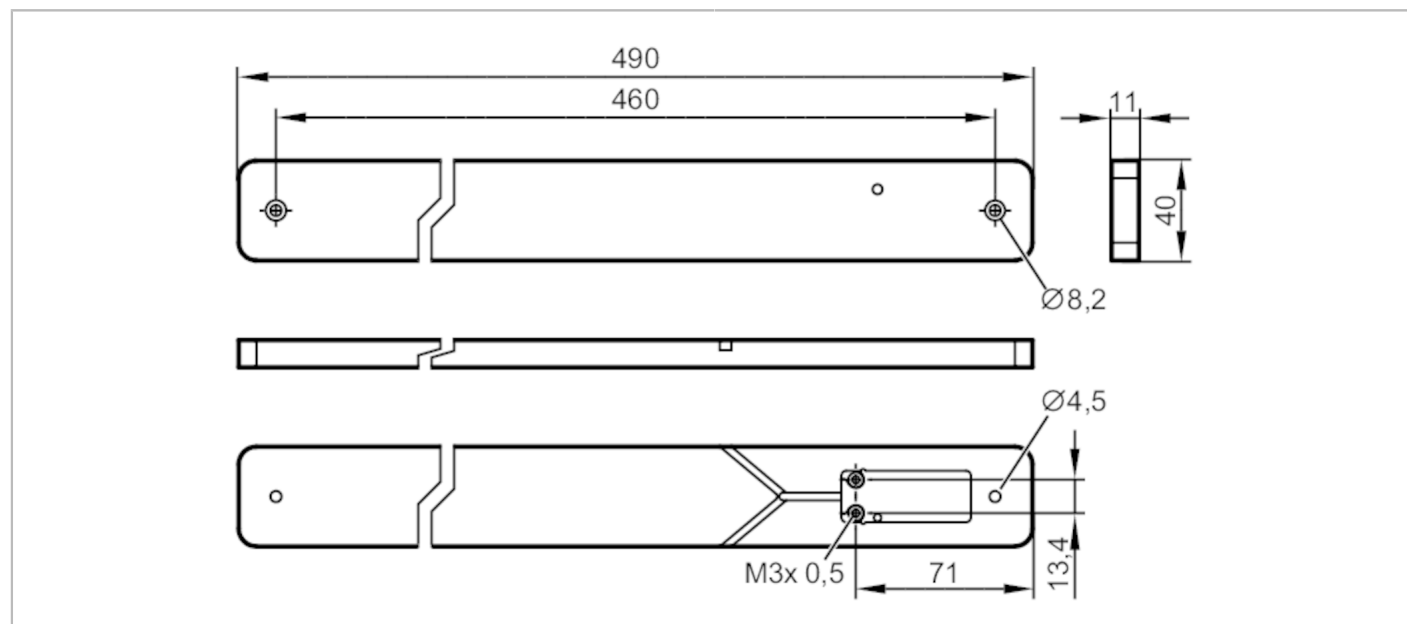

Električni podatki

Delovna frekvenca	[MHz]	13,56
-------------------	-------	-------

Pogoji okolja

Temperatura okolice	[°C]	-20...60
Skladiščna temperatura	[°C]	-20...60

Mehanski podatki

Teža	[g]	370,5
Materiali		POM
Pritezni vrtilni moment	[Nm]	0,5

Opombe

Embalažna enota	1 Kosov
-----------------	---------

Drugi podatki

Tag E80371 (30 mm)

Antena	razpon brez kovine			
ANT515 / ANT516 + E80392	30 mm			

Tag E80384 (50 mm)

Antena	razpon brez kovine			
ANT515 / ANT516 + E80392	50 mm			

E80392



Adapter antene RFID za povečanje hitrosti pomikanja

ANT-AMP/490x40/KQ

Tag E80320 (ISO kartica)

Antena	razpon brez kovine			
ANT515 / ANT516 + E80392	75 mm			