


IGA3008-BPKG/55V



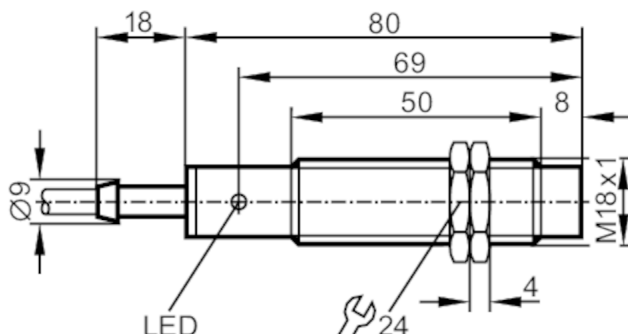

Induktivni senzor

IGA3008-BPKG/55V

Pogoji okolja		
Temperatura okolice	[°C]	-25...80
Zaščita		IP 67
Dovoljenja/preverjanja		
EMC	EN 60947-5-2	
	EN 55011	razred B
MTTF	[Let]	1719
Mehanski podatki		
Teža	[g]	155,9
Ohišje		Izvedba navoja
Vrsta montaže		ne-vezilno vgradno
Mere	[mm]	M18 x 1 / L = 80
Oznaka navoja		M18 x 1
Materiali		medenina prevlečeno z belim bronom; PC
Prikazi/upravljalni elementi		
Prikaz	stikalno stanje	1 x LED, rumeno
Pribor		
V sklopu dobave		zaskočne matice: 2
Opombe		
Embalažna enota		1 Kosov
Električni priključek		
Kabel: 2 m, PVC; 3 x 0,5 mm²		
Priključek		



BN = Barva žil :
 BU = rjavo
 BK = modro
 črn