




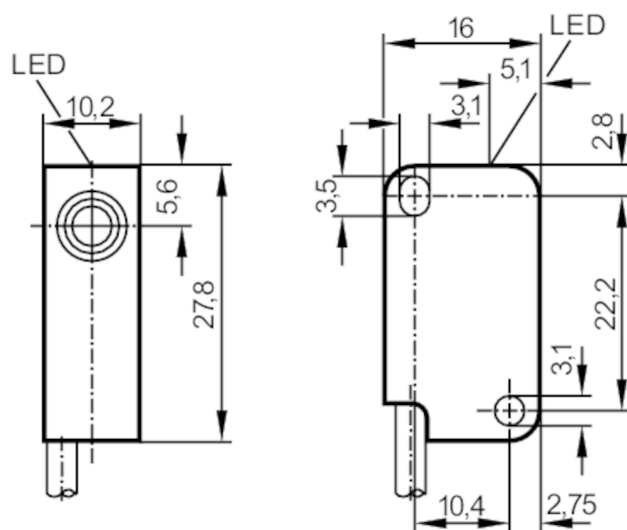

Induktiver NAMUR-Sensor

IS-2002-N/1D/1G/2G

Histereza	[% Sr]	1...15
Zdrs preklompne točke	[% Sr]	-10...10
Pogoji okolja		
Temperatura okolice	[°C]	-20...70
Zaščita		IP 67
Dovoljenja/preverjanja		
Odobritev	PTB 02 ATEX 2217; BVS 04 ATEX E 153 X; IECEX BVS 06.0003X	
Oznaka ATEX	II 1G Ex ia IIB T6 Ga Ta -20...70°C	
	II 2G Ex ia IIC T6 Gb Ta -20...70°C	
	II 1D Ex ia IIIC T20090°C Da Ta: -20...70°C	
	II 1D Ex ia IIIC T200100° C Da Ta: -20...80°C	
EMC	EN 60947-5-6	
Odpornost na udarce/ vibracije	30 g (11 ms) / 10-55 Hz (1 mm)	
MTTF	[Let]	4494
Varnostne karakteristike		
Maks. notranja kapacitivnost	[nF]	80
Maks. notranji indukcijski upor	[μH]	110
Mehanski podatki		
Teža	[g]	79,5
Ohišje	kvadrasto	
Vrsta montaže	vezilno vgradno	
Mere	[mm]	28 x 10 x 16
Materiali	PBT	
Prikazi/upravljalni elementi		
Prikaz	stikalno stanje	1 x LED, rdeče
Opombe		
Embalažna enota	1 Kosov	

NS5003



Induktiver NAMUR-Sensor

IS-2002-N/1D/1G/2G

Električni priključek

Kabel: 2 m, PVC; 2 x 0,14 mm²

Priključek



BN = Barva žil :
BU = rjavo
modro