




AS-Interface PLC

ControllerE M4 2Master RS232

Article no longer available - archive entry

Alternative articles: AC1402 or AC1404
When selecting an alternative article and accessories please note that technical data may differ!

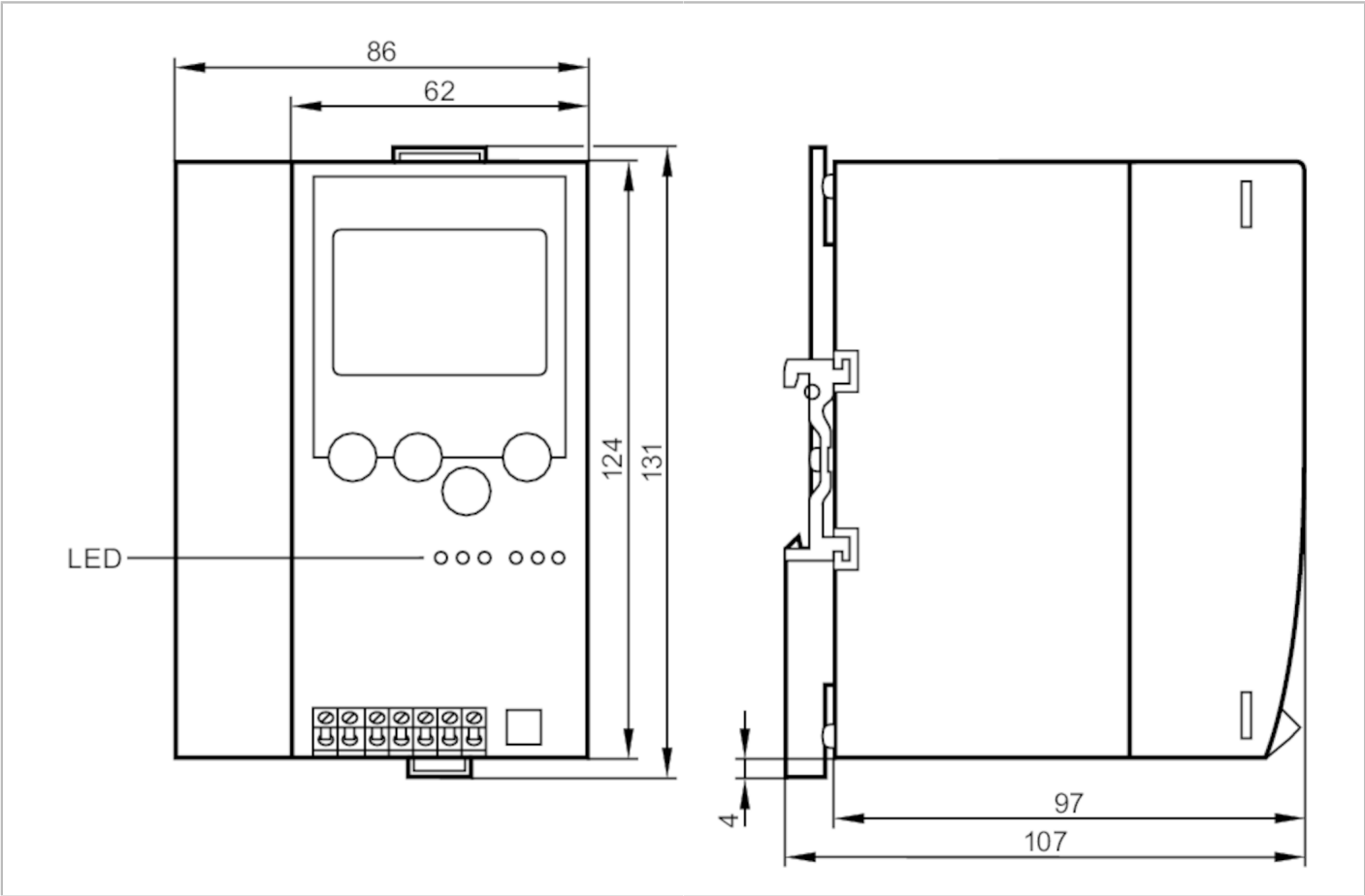

Application		
Application		decentralised controller
Electrical data		
Operating voltage	[V]	24 DC
Insulation rating	[V]	500
Current consumption	[mA]	< 500
Max. current consumption from AS-i	[mA]	10
Max. power consumption	[VA]	10
Number of AS-i masters		2
Electrical separation		yes
Interfaces		
Communication interface		RS232
RS232		
Number of R232 interfaces		1



AS-Interface PLC

ControllerE M4 2Master RS232

Transmission rate	9600...115200 Baud
Connector type	RJ11
Usage type	programming
Note on interfaces	electrically isolated

Operating conditions

Ambient temperature [°C]	0...60
Storage temperature [°C]	-20...70
Protection	IP 20

AS-i classification

AS-i version	2.11; 3.0
AS-i master profile	M4

Mechanical data

Weight [g]	537
Housing	housing for DIN rail mounting
Materials	aluminium; steel sheet galvanised

Displays / operating elements

Display	function	2 x LED, red
		3 x LED, green
		3 x LED, yellow
		full graphic LCD display

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Connection

