


Y-splitter

ZDO2H050MSS0000-00STGH050MSS

Article no longer available - archive entry

Alternative articles: EBC114

When selecting an alternative article and accessories please note that technical data may differ!

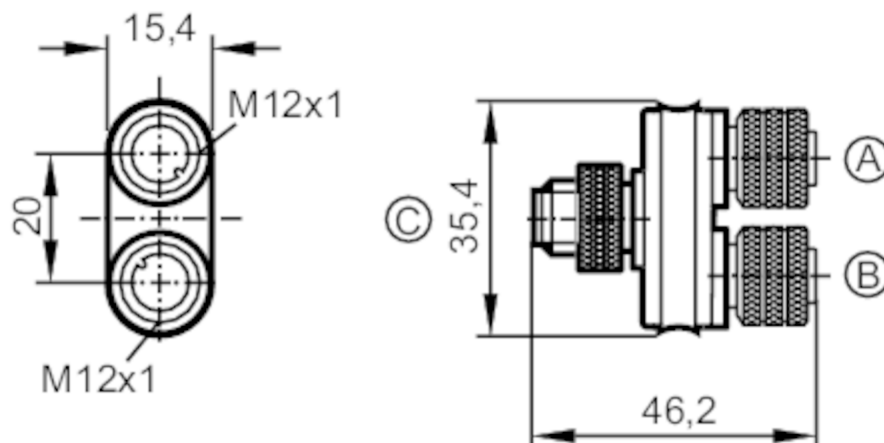

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	31.8
Dimensions	[mm]	15.4 x 35.4 x 46.2
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Connector type		M12

Remarks

Remarks	output A nut PTFE-coated (black)
	output B nut nickel-plated

E10803



Y-splitter


ZDO2H050MSS0000-00STGH050MSS

Pack quantity


1 pcs.

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

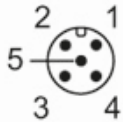

Connection

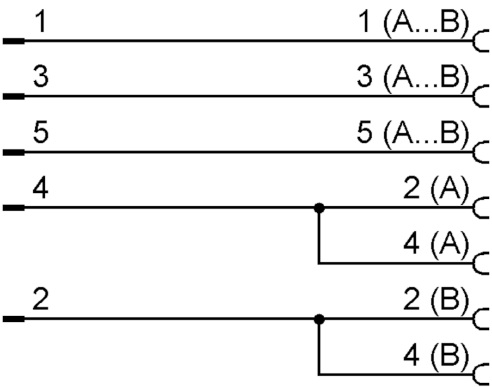

Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

