


Connecting cable with socket

ADOGB030VAS0020E03

Article no longer available - archive entry

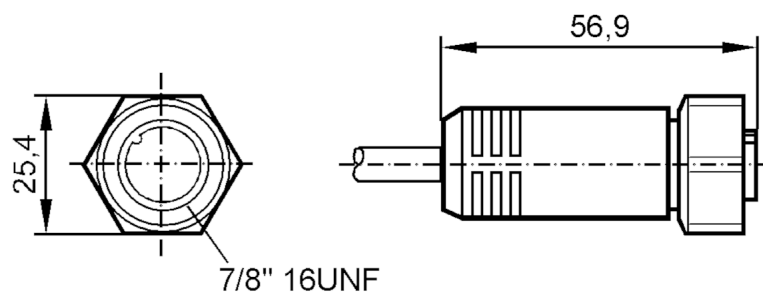

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-20...105

Protection

IP 68

Mechanical data

Weight

[g]

5238.988

Materials

PVC

Moulded-body material

PVC

Material nut

stainless steel (1.4404 / 316L)

Remarks

Pack quantity

1 pcs.

E18166



Connecting cable with socket

ADOGB030VAS0020E03

Electrical connection


Cable: 20 m, PVC, grey; 3 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

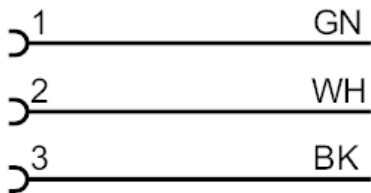

BK =	Core colours :
GN =	black
WH =	green
	white