


E3M124



Connection cable

MCI CONNECTION CABLE 2M ANGLED

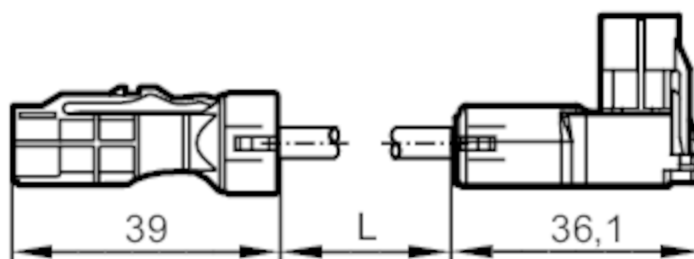

Application	
Special feature	Drag chain suitability
Electrical data	
Operating voltage [V]	< 50 AC / < 75 DC
Operating conditions	
Ambient temperature [°C]	-40...105
Protection	IP 67
Mechanical data	
Weight [g]	89.75
Drag chain suitability	yes
Drag chain suitability	bending radius for fixed installation ≥ 40 mm
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 2 m, TPU, black	