


E11157



Jumper cable with valve plug

VVDAB031--S01,5H03STGH030MSS

Article no longer available - archive entry

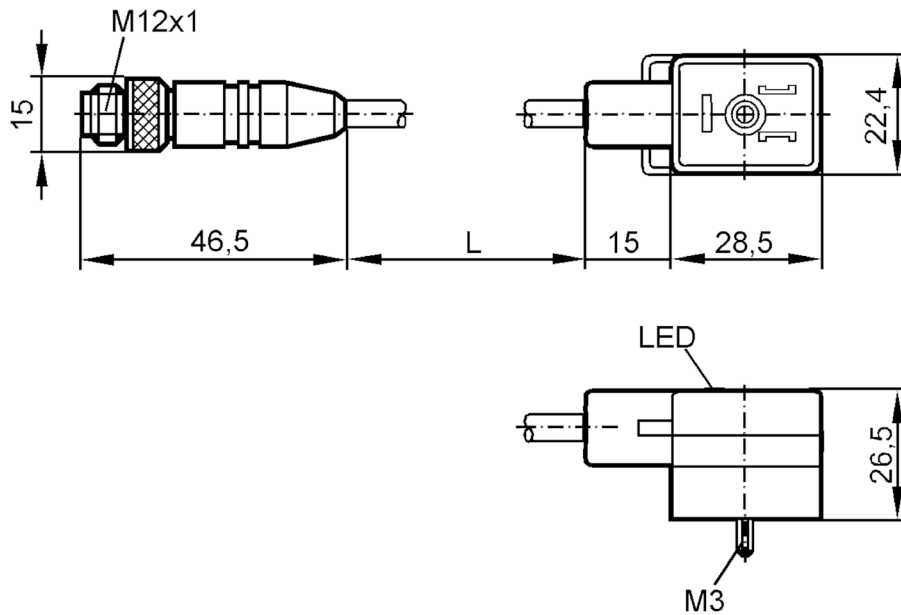

Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Material nut		brass, nickel-plated / brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
Accessories		
Accessories (supplied)		screw panel for labelling
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		


Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated

E11157



Jumper cable with valve plug

 
VVDAB031--S01,5H03STGH030MSS



Electrical connection

Cable: 1.5 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection

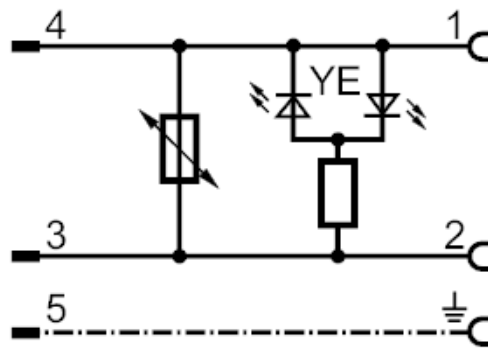

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry