

E20215




Fibre optic diffuse reflection sensor

FT-00-M6

discontinued article

Discontinuation date: 31.03.2017

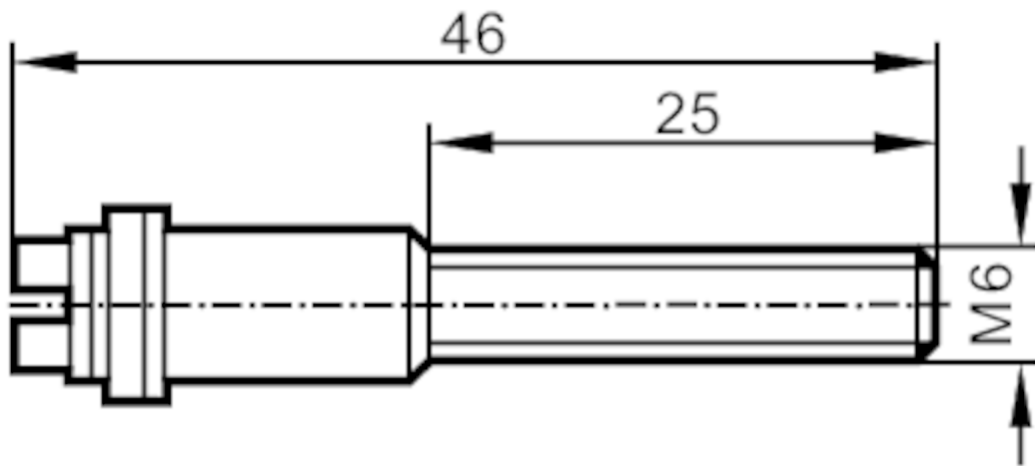

Application

Function principle Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type OKF; OUF; OOF

OKF

Range fibre optics [mm] 40

OOF

Range fibre optics [mm] 200

OUF

Range fibre optics [mm] 40

Operating conditions

Ambient temperature [°C] -25...80

E20215



Fibre optic diffuse reflection sensor

FT-00-M6

Mechanical data	
Weight [g]	20.7
Version of sensing head	straight; with adapter for direct mounting
Total length [mm]	26
Fibre arrangement	Ⓜ
Fibre material	glass
Fibre head material	stainless steel (1.4305 / 303)
Accessories	
Accessories (supplied)	hexagon nuts: 4 x M6, stainless steel
	tooth lock washers: 2
	knurled nut: 1 x M11
Remarks	
Notes	discontinued article
Pack quantity	1 pcs.

discontinued article

Discontinuation date: 31.03.2017