




UCR007

Cable set
for CabinetModules
CR2012 and CR2014

includes
1 x EC1520
2 x EC1523

Core length 1.20 m
Core cross-section 1 mm²

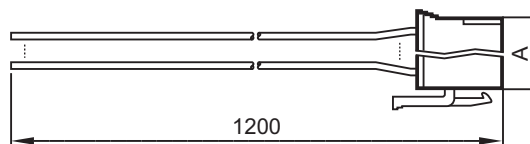

Technical data

Cores

Type of core

Core length

Core cross-section

Core diameter

Insulation material

Conductor resistance

Temperature range

Core colour

Core arrangement

Connection

Connectors

Protection

Material (housing)

Material (contacts)

for
CR2012 and CR2014

FLRY-B 1.0
(symmetrical design, flexible)
according to standards DIN 72551, parts 5/6 and DIN ISO 6722

1.20 m

1 mm²

2 mm

PVC

17...18.50 mΩ/m at 20 °C

-40...105 °C

white with black imprint

odd and even cores are tied by means of a cable tie
(e.g. core no. 1, 3, 5 and 2, 4, 6)

AMP (socket), lock function and reverse-polarity protection

IP 20

PBT (black)

CuSn (tin-plated)

	Pin connection	A [mm]	poles	number
EC1520		16	6	1
EC1521		26	10	–
EC1522		36	14	–
EC1523		46	18	2