


AS-Interface AirBox

AirBox 2DI 1PO M12 ATEX

Article no longer available - archive entry

Alternative articles: AC246A + E7000A

When selecting an alternative article and accessories please note that technical data may differ!

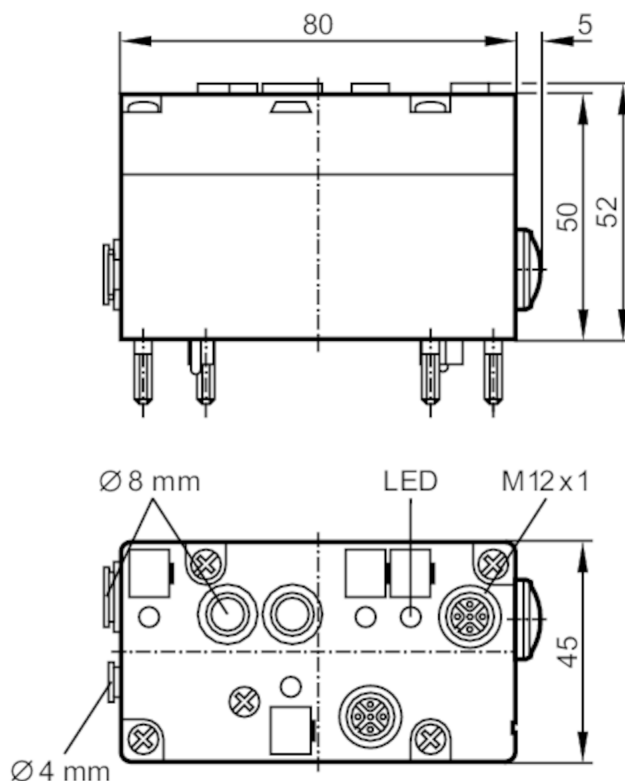

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	165
Integrated watchdog		yes

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 2; Number of pneumatic outputs: 1
------------------------------	---

Inputs

Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Подача напруги	[V]	20...30
Max. total current rating of inputs	[mA]	100
Input current High	[mA]	> 3
Input current Low	[mA]	< 1.5
Switching level high	[V]	> 10

AC046A



AS-Interface AirBox

AirBox 2DI 1PO M12 ATEX

Digital inputs protected against short circuits	yes				
Outputs					
Electrical design	AS-i				
Number of pneumatic outputs	1				
Operating conditions					
Ambient temperature	[°C]	0...40			
Note on ambient temperature	with special compressed air treatment: < 0 °C				
Protection	IP 65				
Tests / approvals					
ATEX marking	 II 3D T 65 °C IP 65 X				
EMC	EN 50295				
AS-i classification					
AS-i profile	S-3.F				
AS-i I/O configuration	[hex]	3			
AS-i ID code	[hex]	F			
AS-i certificate pending	yes				
Assignment of the data bits	data bit	D0	D1	D2	D3
	socket	I-1	I-1 / I-2	O-3	-
	pin	4	2 / 4	-	-
Mechanical data					
Type of mounting	screw mounting				
Materials	PBT				
Pneumatic system	1 x 4/2-way seat valve				
Operating pressure range	[bar]	3...8			
Operating pressure range	[MPa]	0.3...0.8			
Note on working pressure range	incl. possible pressure peaks				
Air flow at 6/5 bar	[l/min]	500			
Air flow at 6/0 bar	[l/min]	700			
Permissible compressed air	filtered (5 µm); lubricated (ISO-VG10) or not lubricated				
Auxiliary air 90 % vacuum	[bar]	3...8			
Auxiliary air 90 % vacuum	[MPa]	0.3...0.8			
Tube fittings	Legris LF 3000/8 / LF 3000/4				
Exhaust	integrated exhaust				
Displays / operating elements					
Display	operation	LED, green			
	function	LED, yellow			
Аксессуары					
Accessories (optional)	Module lower part:, AC5000				
Remarks					
Remarks	Use M12 connectors with hexagon nuts, tightening torque 0.8 Nm.				
Pack quantity	1 pcs.				

AC046A



AS-Interface AirBox

AirBox 2DI 1PO M12 ATEX

Electrical connection

Connection

Connector: M12