




AS-Interface automation set for pneumatic valve
actuators

Added Value package AS-i T5

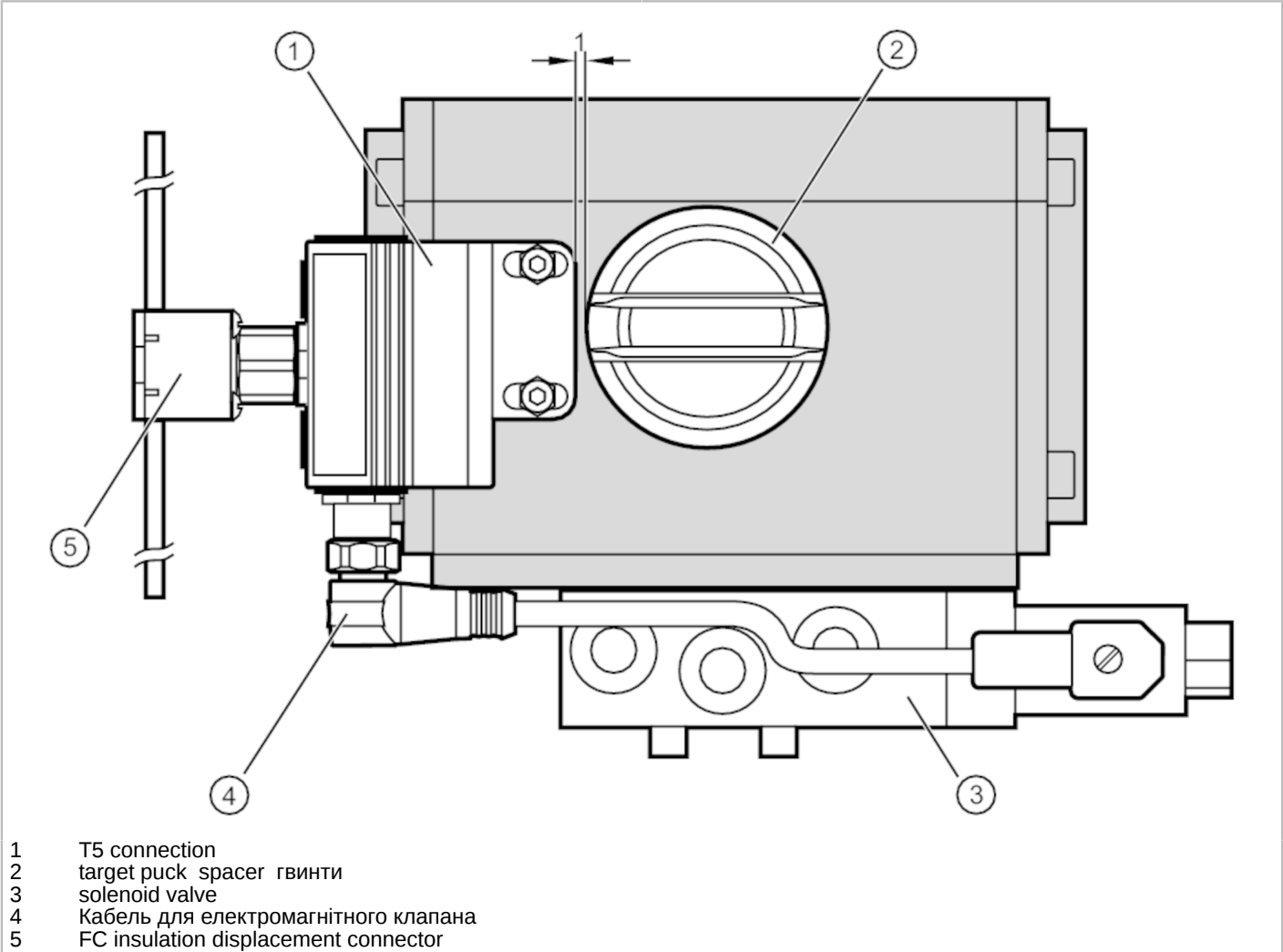

- 1 T5 connection
- 2 target puck spacer гвинти
- 3 solenoid valve
- 4 Кабель для электромагнитного клапана
- 5 FC insulation displacement connector

Product characteristics	
Output function	PNP
Sensing range [mm]	4
Electrical data	
Max. current consumption from AS-i [mA]	160
Operating voltage AUX DC [V]	26.5...31.6; ("supply class 2" to cULus)
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 1
Inputs	
Number of digital inputs	2
Outputs	
Number of digital outputs	1
Output function	PNP
Detection zone	
Sensing range [mm]	4
AS-i classification	
AS-i version	2.1



AS-Interface automation set for pneumatic valve actuators

Added Value package AS-i T5

AS-i profile		S-7.A.E
AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	A.E

Mechanical data

Weight	[g]	1056.5
Mounting		non-flush mountable
Hole spacing	[mm]	80
Shaft height of valve drive	[mm]	20

Аксессуары

Items supplied	dual sensor for actuator feedback: 1, AC2316
	Target pucks: 1, E12517
	spacer: 1, E12526
	Flat cable insulation displacement connector: 1, E75471
	solenoid valve: 1, Norgren Herion 2623079303602400
	silencer: 2, 0014600
	Connection cable: 1, E10817

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Electrical connection - plug




Connection

Connection

1	AS-i +
3	AS-i -

Electrical connection - socket

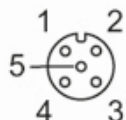

Outputs

3	external voltage -
4	switching output 1 +