




AS-Interface PLC

CONTR 1MSTR 1RS232C

Article no longer available - archive entry

Alternative articles: AC1333

When selecting an alternative article and accessories please note that technical data may differ!

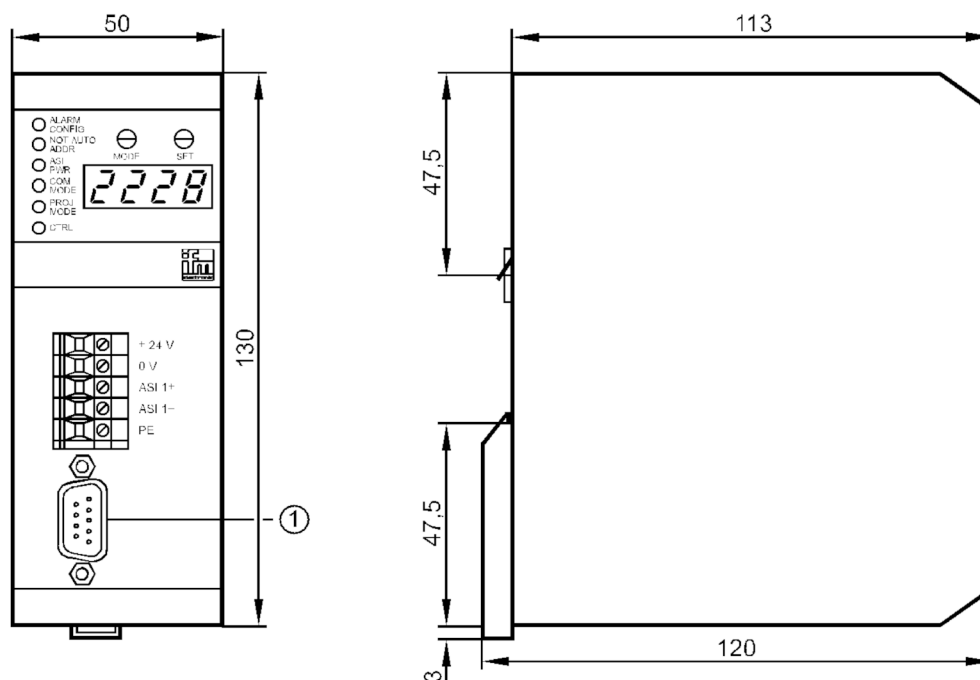

1 serial interface RS232C



Application

Application mini-controller for signal preprocessing

Electrical data

Operating voltage	[V]	22...30 DC; (24 DC ; to PELV)
Insulation rating	[V]	500
Max. power consumption	[VA]	10
Electrical separation		yes

Outputs

Electrical design AS-i

Interfaces

Communication interface RS232

RS232

Number of R232 interfaces	1
Transmission rate	4800...62400 Baud
Connector type	SUB-D
Usage type	programming

Operating conditions

Ambient temperature	[°C]	0...60
Storage temperature	[°C]	-20...70



AS-Interface PLC

CONTR 1MSTR 1RS232C

Max. relative air humidity	[%]	95
Protection		IP 20

Tests / approvals

Shock/vibration resistance	< 15 g (11ms) / < 55 Hz (0.5mm)
----------------------------	---------------------------------

AS-i classification

AS-i profile	M1
AS-i certificate	22502

Mechanical data

Housing	housing for DIN rail mounting
Materials	aluminium

Displays / operating elements

Display	function	2 x LED, red
		2 x LED, green
		2 x LED, yellow

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

screw terminals: 5 x

Connection

5	+ 24 V
4	0 V
3	AS-i 1+
2	AS-i 1–
1	PE