




AS-Interface diagnosis module

AS-i Tuner IP67

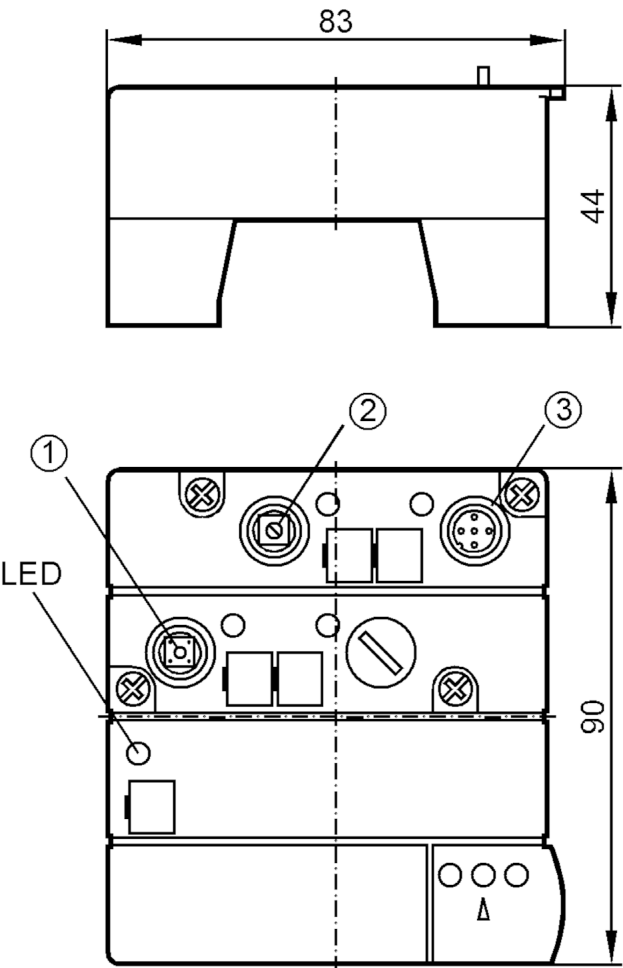

- 1 tune button
- 2 rotary switch
- 3 AS-i distribution socket M12



 
Application		
Application		diagnostic tool for AS-i
Electrical data		
Nominal voltage DC	[V]	26.5...31.6
Max. current consumption from AS-i	[mA]	60
Reverse polarity protection		yes
Undervoltage monitoring		yes
Operating conditions		
Ambient temperature	[°C]	0...55
Protection		IP 67
Tests / approvals		
MTTF	[ANN]	140
Mechanical data		
Weight	[g]	199.2

AC1146



AS-Interface diagnosis module

AS-i Tuner IP67

Materials		PBT
Displays / operating elements		
Display	operation	LED, green
	warning	LED, yellow
	errors	LED, red
Аксессуары		
Accessories (optional)	Module lower part:, AC5000	
Remarks		
Remarks	no addressing required	
	current rating of the AS-i distribution socket max. 1 A	
Pack quantity	1 pcs.	
Electrical connection		
contact pins to module lower part, FK:		
Connector: M12; coding: A		
		
1	AS-i distribution socket M12	
3	AS-i +	
3	AS-i -	