


AC1150



AS-Interface module for frequency inverter

2DI RS485 SEW CCT

phase-out article

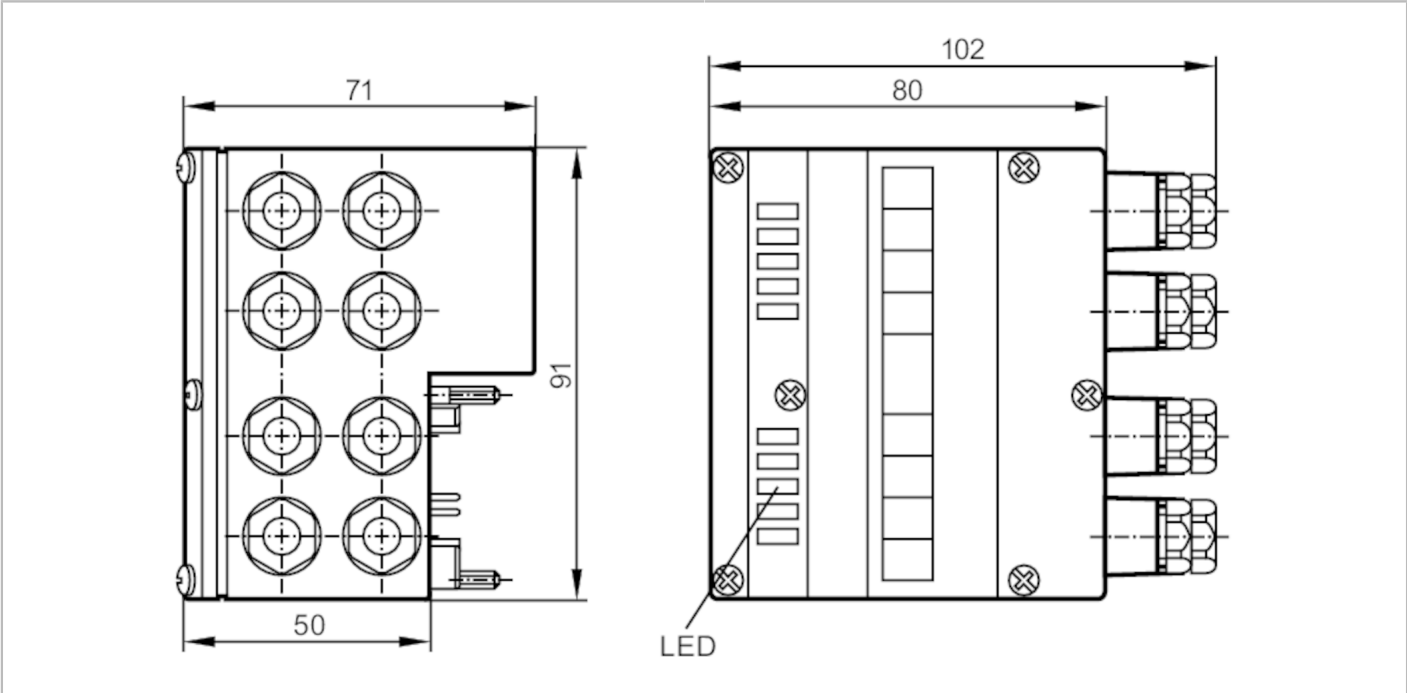

Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	80
Reverse polarity protection		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AUX
Подача напруги	[V]	20...30
Max. total current rating of inputs	[mA]	26
Input current High	[mA]	> 5
Input current Low	[mA]	< 1
Operating conditions		
Ambient temperature	[°C]	0...55
Protection		IP 65
Tests / approvals		
EMC	EN 50295	

AC1150



AS-Interface module for frequency inverter

2DI RS485 SEW CCT

AS-i classification

AS-i master profile	M2; M3; M4				
AS-i profile	S-7.F				
AS-i I/O configuration [hex]	7				
AS-i ID code [hex]	F				
Assignment of the data bits	data bit	D0	D1	D2	D3
	function	motor stopped/ running	error message	input 1	input 2

Mechanical data

Weight [g]	286.7
Type of mounting	AS-i interface to FC-E lower parts
Materials	PBT

Displays / operating elements

Display	switching status	LED, yellow
	operation	LED, green
	short circuit	LED, red
	function	LED, red

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

contact pins to module lower part, FK-E: