


Article no longer available - archive entry

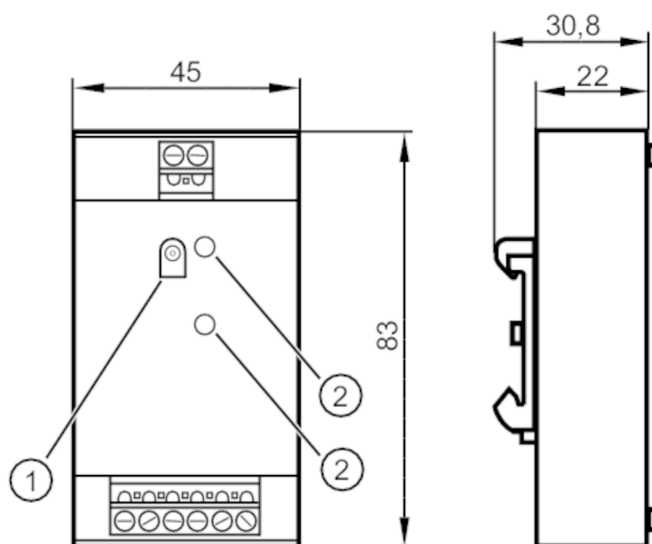

- 1 addressing plug
2 LED

**Electrical data**

Operating voltage	[V]	19.5...31.6 DC
Max. current consumption from AS-i	[mA]	100
Reverse polarity protection		yes

Operating conditions

Ambient temperature	[°C]	0...60
Protection		IP 30

Tests / approvals

EMC	IEC 62026-2	
-----	-------------	--

AS-i classification

AS-i version		3.0
Розширений режим адресації		yes
AS-i profile		S-B.A.5
AS-i I/O configuration	[hex]	B
AS-i ID code	[hex]	A.5

Mechanical data

Weight	[g]	98.5
Type of mounting		mounting on DIN rail
Dimensions	[mm]	83 x 22 x 45
Materials		PBT

AC1155



AS-i RS485 gateway

AS-i / RS-485 Gateway

Displays / operating elements

Display	operation	LED, green
	short circuit	LED, red

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

A+	AS-i +
A-	AS-i -
B	(CTS)
A	(RTS)
GND	
GND	not used
TxD	not used
RxD	not used