

AC1206




AS-Interface power supply

PowerSupply 230VAC 2,8A

Article no longer available - archive entry

Alternative articles: AC1256

When selecting an alternative article and accessories please note that technical data may differ!

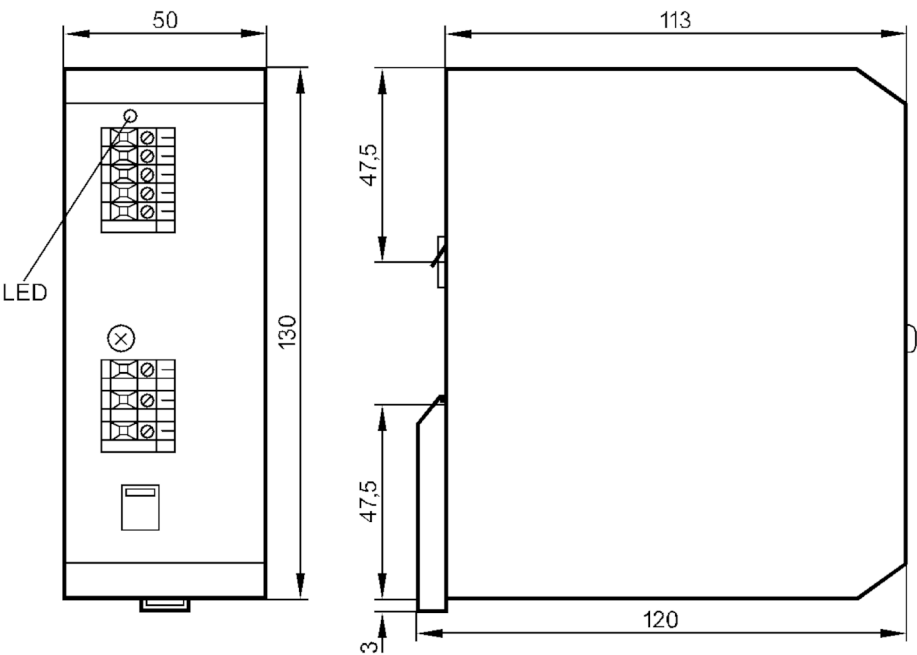

Electrical data

Nominal voltage AC	[V]	110 / 230; (selectable)
Nominal frequency AC	[Hz]	47...63
Input voltage range AC	[V]	88...132 / 184...264
Output voltage DC	[V]	29.5...31.6
Max. power-on delay time	[ms]	42
Max. output current at min. output voltage	[A]	2.8
Number of output circuits		1
Max. residual ripple	[mV]	50
External input protection		> 6 A
Fuse	[A]	2.5; (not accessible)
Derating	[W/K]	1 (60...70 °C)
Integrated data decoupling		yes

Outputs

Short-circuit protection	yes
Overload protection	yes
Parallel connection of outputs possible	no
Series connection of outputs possible	no

AC1206



AS-Interface power supply

PowerSupply 230VAC 2,8A

Operating conditions

Ambient temperature	[°C]	-10...60
Protection		IP 20

Tests / approvals

EMC	EN 60950/A2 1993	
	EN 50081-1	
	EN 61000-6-2	

AS-i classification

AS-i certificate	15901
------------------	-------

Mechanical data

Materials	aluminium
-----------	-----------

Displays / operating elements

Display	function	LED, green
---------	----------	------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...2.5 mm²

Connection

