




AS-Interface CompactLine module

CompactM12 2 AI C V4A

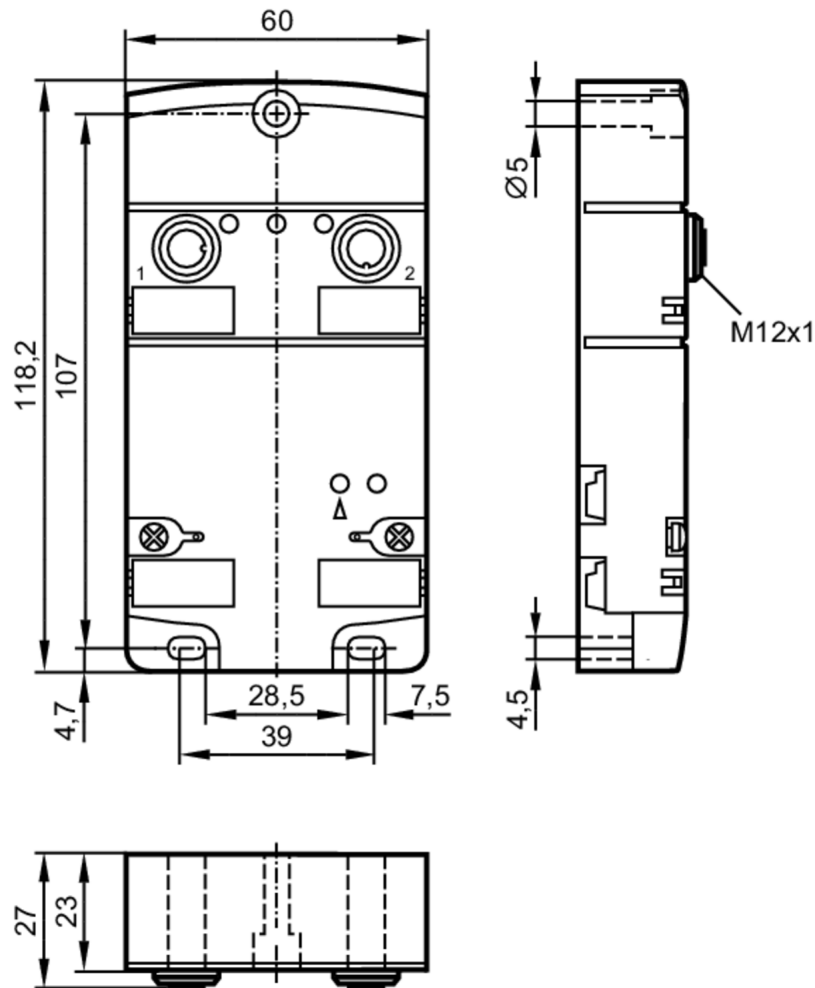

Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	250
Reverse polarity protection		yes
Inputs / outputs		
Number of inputs and outputs		Number of analogue inputs: 2
Inputs		
Max. total current rating of inputs	[mA]	200
Number of analogue inputs		2; (Anschluss von 2- und 3-Draht-Sensoren)
Analogue input (current)	[mA]	4...20
Operating conditions		
Ambient temperature	[°C]	-25...80



AS-Interface CompactLine module

CompactM12 2 AI C V4A

Storage temperature	[°C]	-25...80
Max. relative air humidity	[%]	90; (non condensing)
Max. height above sea level	[m]	2000
Protection		IP 67; (when flat cables are used E7400x / E7401x)
Tests / approvals		
EMC		EN 61000-6-2
		EN 62026-2
		EN 50581
MTTF	[ANN]	167
UL approval		подача напруги Class 2
AS-i classification		
AS-i version		2.11; 3.0
AS-i addressing		IR addressing possible
Розширений режим адресації		no
AS-i master profile		M3; M4
AS-i profile		S-7.3.D
AS-i I/O configuration	[hex]	7
AS-i ID code	[hex]	3.D
AS-i certificate		99101
Mechanical data		
Weight	[g]	275.5
Type of mounting		AS-i flat cables directly connectable
Materials		PA; socket: stainless steel (1.4404 / 316L); threaded inserts in the lower part: stainless steel (1.4404 / 316L); screws in the lower part: stainless steel (1.4578 / 316Cu); piercing contacts: CuSn6 nickel-plated and tin-plated
Displays / operating elements		
Display	operation	LED, green Voltage AS-i
	errors	LED, red
	function	LED, yellow channels AI1, AI2
Electrical connection		
Module connection		Приладдя
Аксессуары		
Accessories (optional)		Protective cap: M12, E73004
		Stainless steel sleeve, for installation in case of high mechanical stress , E70402
Remarks		
Remarks		When the actuators are supplied from AS-i the load must not exceed a maximum of 200 mA.
		There is an electrical connection between the sensor and AS-i.
		The module is exclusively supplied via the yellow AS-i cable.
Pack quantity		1 pcs.




AS-Interface CompactLine module

CompactM12 2 AI C V4A

Electrical connection

Connector: M12; coding: A

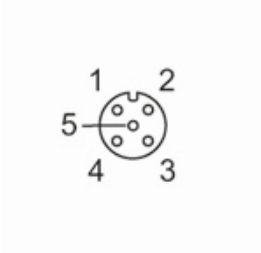

1	Sensor supply +24V
2	analogue input AI +
3	Sensor supply 0V / analogue input AI-
5	functional earth