




AS-Interface CompactLine module

CompactModule 4 SB

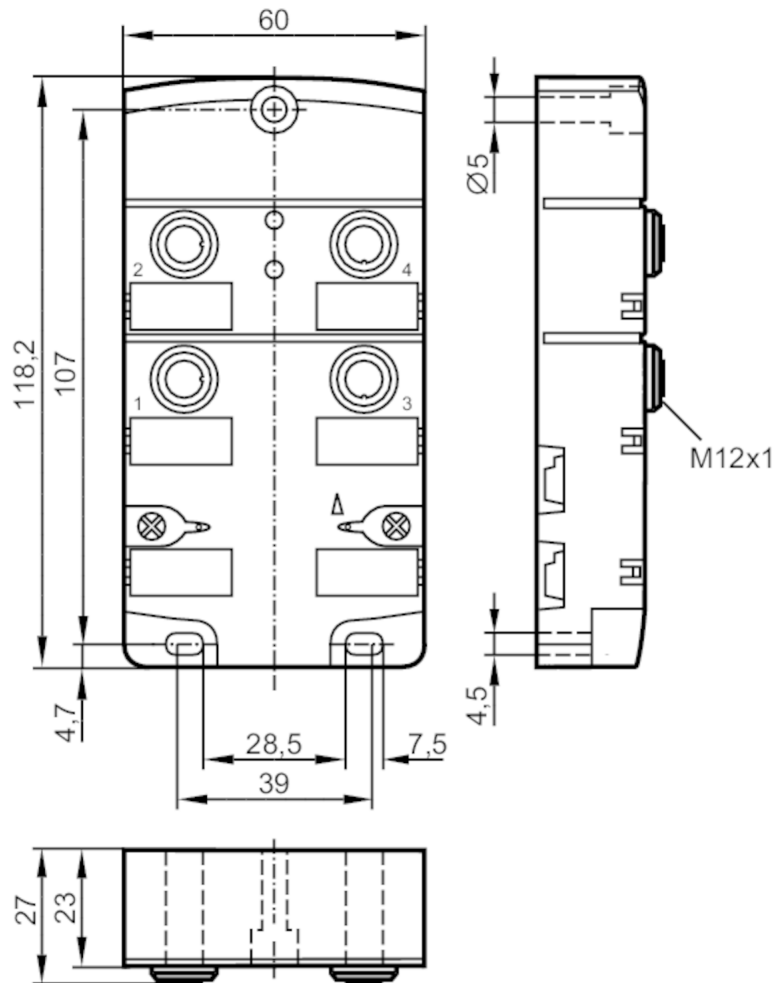

Application

Application

field installation

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	2000
Max. current load total	[A]	4
Additional voltage supply	[V]	20...30 DC; (AUX)
Max. current consumption from additional supply	[mA]	2000; (AUX)

Operating conditions

Ambient temperature	[°C]	-25...80
Storage temperature	[°C]	-25...80
Max. relative air humidity	[%]	90; (non condensing)
Max. height above sea level	[m]	2000
Protection		IP 67; (when flat cables are used E7400x / E7401x)

AC2413



AS-Interface CompactLine module

CompactModule 4 SB

Tests / approvals												
EMC	EN 61000-6-2											
	EN 62026-2											
	EN 50581											
UL approval	подача напруги	Class 2										
Mechanical data												
Weight	[g]	272.5										
Type of mounting	AS-i flat cables directly connectable											
Dimensions	[mm]	118.2 x 60 x 27										
Materials	PA 6.6; socket: brass nickel-plated; threaded inserts in the lower part: brass nickel-plated; O-ring: FKM; piercing contacts: CuSn6 nickel-plated and tin-plated											
Electrical connection												
Module connection	Приладдя											
Аксессуары												
Accessories (optional)	Stainless steel sleeve, for installation in case of high mechanical stress , E70402											
Remarks												
Pack quantity	1 pcs.											
Electrical connection												
Connector: M12; coding: A												
<table><tr><td>1</td><td>AS-i +</td></tr><tr><td>2</td><td>external voltage -</td></tr><tr><td>3</td><td>AS-i -</td></tr><tr><td>4</td><td>external voltage +</td></tr><tr><td>5</td><td>protective earth (FE)</td></tr></table>			1	AS-i +	2	external voltage -	3	AS-i -	4	external voltage +	5	protective earth (FE)
1	AS-i +											
2	external voltage -											
3	AS-i -											
4	external voltage +											
5	protective earth (FE)											