


AS-Interface CompactLine module

Compactmodul aktiv, 4AT PNP 2A

Article no longer available - archive entry

Alternative articles: AC2465

When selecting an alternative article and accessories please note that technical data may differ!

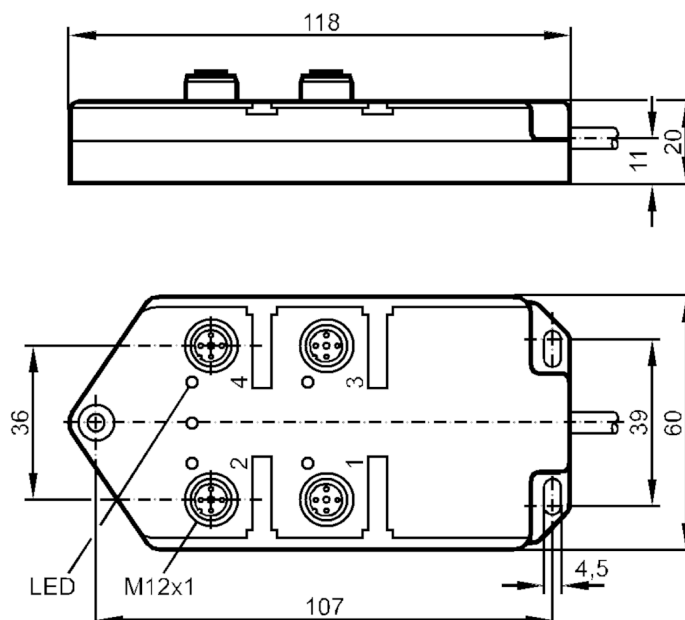

Application

Application

field installation

Electrical data

Operating voltage [V] 26.5...31.6 DC

Current consumption [mA] < 75

Max. current load total [A] 4

Integrated watchdog yes

Inputs / outputs

Number of inputs and outputs

Number of digital outputs: 4

Outputs

Electrical design AS-i

Number of digital outputs 4

Circuit PNP

Voltage range DC [V] 10...30; (to PELV; via round cable)

Max. current load per output [mA] 2000

Short-circuit proof yes

Electrically separated yes

Operating conditions

Ambient temperature [°C] -25...80



AS-Interface CompactLine module

Compactmodul aktiv, 4AT PNP 2A

Protection	IP 67
------------	-------

Tests / approvals

EMC	EN 50295
-----	----------

AS-i classification

AS-i profile	S-8.0				
AS-i I/O configuration [hex]	8				
AS-i ID code [hex]	0				
AS-i certificate	08901				
Assignment of the data bits	data bit	D0	D1	D2	D3
	socket	O-1	O-2	O-3	O-4
	pin	4	4	4	4

Mechanical data

Materials	PUR
-----------	-----

Displays / operating elements

Display	operation	LED, green
	function	LED, yellow


Remarks

Pack quantity	1 pcs.
---------------	--------


Electrical connection

Cable: 2 m, PVC; 5 x 1.5 mm²

Connector: M12; coding: A

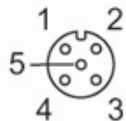

Connection

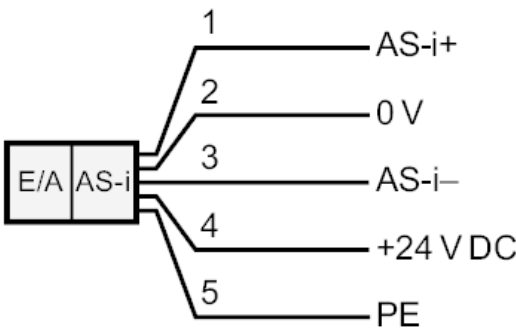

3	external voltage -
4	switching output +
5	protective earth (PE)