


AS-Interface ClassicLine module

ClassicLine45 4 SB

Article no longer available - archive entry

Alternative articles: AC5200

When selecting an alternative article and accessories please note that technical data may differ!

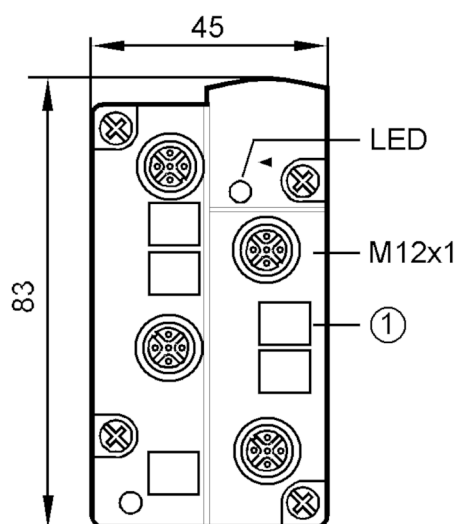

1 panel for labelling



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2

Inputs

Подача напруги	[V]	20...30
----------------	-----	---------

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Weight	[g]	100.4
Type of mounting		AS-i interface to FC lower parts
Materials		PBT

Аксессуары

Accessories (optional)	Module lower part
------------------------	-------------------

Remarks

Pack quantity	1 pcs.
---------------	--------




AS-Interface ClassicLine module

ClassicLine45 4 SB

Electrical connection

Connector: M12; coding: A

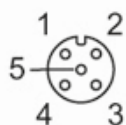

1	AS-i +
2	external voltage -
3	AS-i -
4	external voltage +