




AS-Interface PCB module

AS-i pcb 2-DI/1-DO

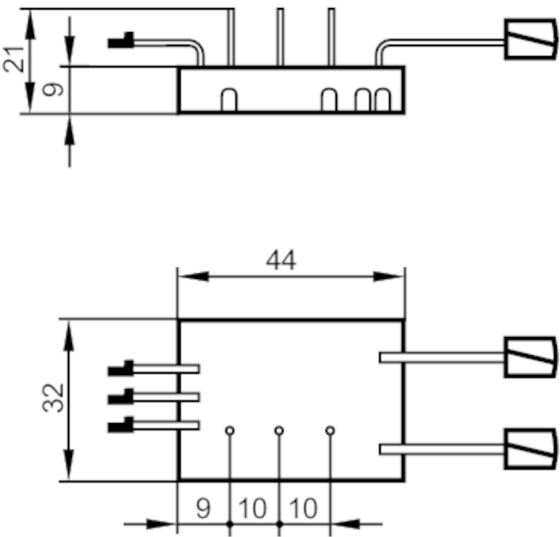

Application		
Application		housing for panel mounting
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 50
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 2
Inputs		
Number of digital inputs		2
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Подача напруги	[V]	18...30; (DC)
Input current High	[mA]	> 5
Digital inputs protected against short circuits		no
Outputs		
Electrical design		PNP
Voltage range DC	[V]	DC
Max. current load per output	[mA]	10
Short-circuit proof		no
Actuator supply outputs		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...60



AS-Interface PCB module

AS-i pcb 2-DI/1-DO

Protection		IP 20; (depending on the housing)				
Tests / approvals						
EMC		EN 50295				
MTTF		[ANN]	842			
AS-i classification						
AS-i version		2.11; 3.0				
Розширений режим адресації		yes				
AS-i master profile		M2; M3; M4				
AS-i profile		S-7.A.E				
AS-i I/O configuration		[hex]	7			
AS-i ID code		[hex]	A.E			
AS-i certificate		75101				
Assignment of the data bits		data bit	D0	D1	D2	D3
		Designation	I-1 / O-1	I-2	-	-
Mechanical data						
Weight		[g]	58.5			
Displays / operating elements						
Display		operation			LED, green	
		errors			LED, red	
		function			LED, yellow	
Remarks						
Pack quantity		1 pcs.				
Electrical connection						
Cable: 0.2 m						
AS-i +	brown					
AS-i -	blue					
I1	black					
I2	black					
O1	red					