




AS-Interface control cabinet module

CabinetModule 4DO R C

Article no longer available - archive entry

Alternative articles: AC2258

When selecting an alternative article and accessories please note that technical data may differ!

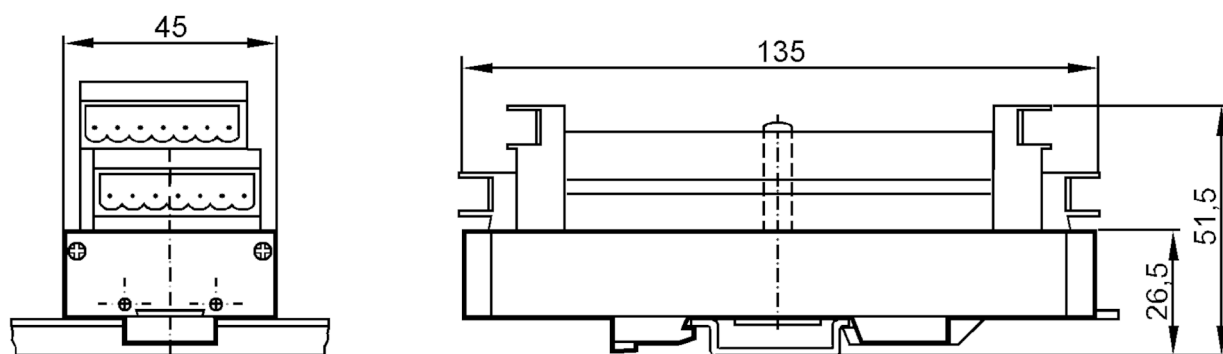

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 60
Max. current load total	[A]	6

Inputs / outputs

Number of inputs and outputs	Number of relay outputs: 4
------------------------------	----------------------------

Outputs

Electrical design		AS-i
Voltage range DC	[V]	24
Voltage range AC	[V]	240
Max. current load per output	[mA]	2500
Number of relay outputs		4
Electrically separated		yes

Operating conditions

Ambient temperature	[°C]	-25...50
Protection		IP 20

Tests / approvals

EMC	EN 50295
	EN 50178



AS-Interface control cabinet module

CabinetModule 4DO R C

AS-i classification

AS-i profile		S-8.0
AS-i I/O configuration	[hex]	8
AS-i ID code	[hex]	0

Mechanical data

Type of mounting		mounting on DIN rail and panel; string mounting possible
Dimensions	[mm]	45 x 135 x 51.5
Materials		PA; PVC

Displays / operating elements

Display	switching status	LED, yellow
	operation	LED, green

Аксессуары

Accessories (optional)	COMBICON connectors:, E70198
------------------------	------------------------------


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

COMBICON:

Connection

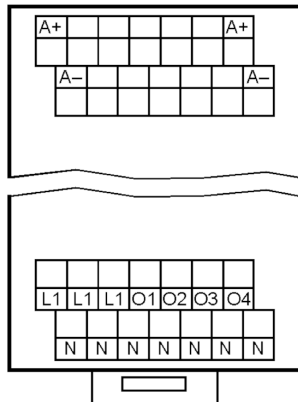

A+	AS-i +
A-	AS-i -
L1	external supply + (DC) / L1 (AC)
N	external supply - (DC) / N (AC)
O1...O4	switching output actuator 1...4