




AS-Interface module

ASI-MODUL-OBERTEIL M12 4AR

Article no longer available - archive entry

Alternative articles: AC5213

When selecting an alternative article and accessories please note that technical data may differ!

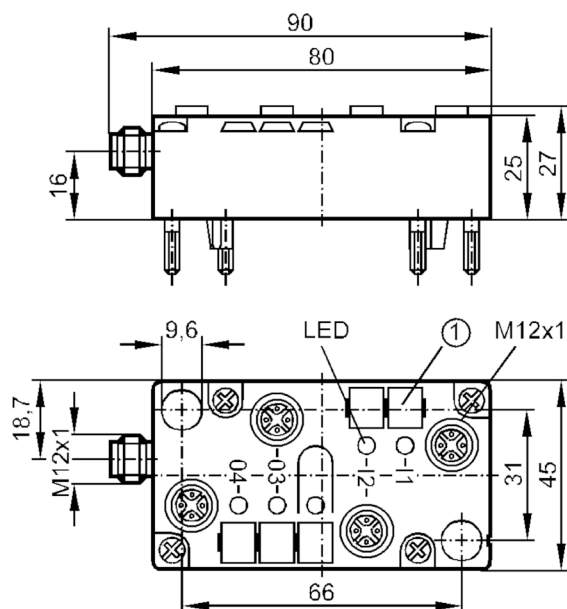

1 panel for labelling



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 35
Max. current load total	[A]	2
Integrated watchdog		no

Inputs / outputs

Number of inputs and outputs	Number of relay outputs: 4
------------------------------	----------------------------

Outputs

Electrical design		AS-i
Voltage range DC	[V]	24; (to PELV; via M12 connector)
Max. current load per output	[mA]	1000
Number of relay outputs		4
Short-circuit proof		no
Electrically separated		yes

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Tests / approvals

EMC	EN 50295
-----	----------

