




AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Article no longer available - archive entry

Alternative articles: AC5215
When selecting an alternative article and accessories please note that technical data may differ!

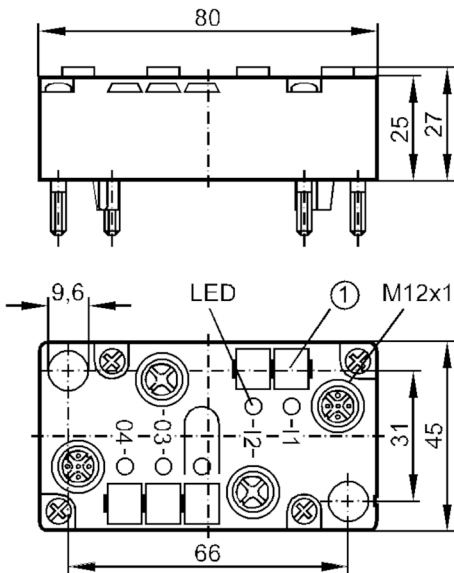

1 panel for labelling



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 4
Inputs		
Number of digital inputs		4; (2 x 2)
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Подача напруги	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	> 5
Input current Low	[mA]	< 1.5
Switching level high	[V]	> 10
Digital inputs protected against short circuits		yes
Outputs		
Electrical design		AS-i



AS-Interface module

Moduloberteil aktiv, 2x2E 200m

Operating conditions						
Ambient temperature		[°C]	-25...85			
Protection			IP 67			
Tests / approvals						
EMC		EN 50295				
AS-i classification						
AS-i profile		S-0.1				
AS-i I/O configuration		[hex]	0			
AS-i ID code		[hex]	1			
AS-i certificate		01302				
Assignment of the data bits		data bit	D0	D1	D2	D3
		socket	I-1/2	I-1/2	I-3/4	I-3/4
		pin	4	2	4	2
Mechanical data						
Type of mounting		AS-i interface to FC lower parts				
Materials		PBT				
Displays / operating elements						
Display		operation		LED, green		
		function		LED, yellow		
Remarks						
Pack quantity		1 pcs.				
Electrical connection						
contact pins to module lower part, FK / PG:						
Connector: M12; coding: A						
