




AS-Interface illuminated pushbutton module

EMS Module 2BI 2LO

Article no longer available - archive entry

Alternative articles: AC2086
When selecting an alternative article and accessories please note that technical data may differ!

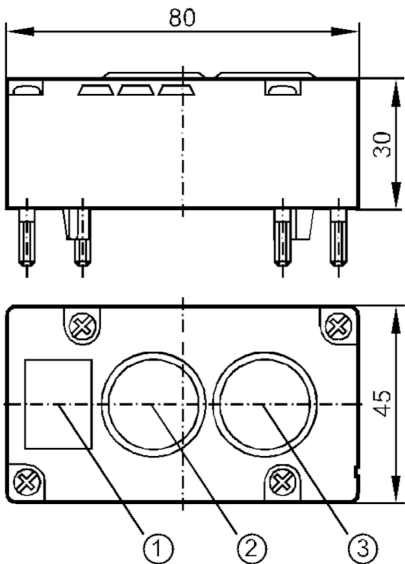

- 1 panel for labelling
- 2 pushbutton / LED
- 3 pushbutton / LED



Application		
Application		field installation
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	55
Inputs		
Sensor supply of the inputs		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...60
Protection		IP 67
Tests / approvals		
EMC	EN 50295	
AS-i classification		
AS-i version		2.1
Розширений режим адресації		no
AS-i master profile		M2; M3; M4



AS-Interface illuminated pushbutton module

EMS Module 2BI 2LO

AS-i profile	S-3.F.F				
AS-i I/O configuration [hex]	3				
AS-i ID code [hex]	F.F				
AS-i certificate	04801				
Assignment of the data bits	data bit	D0	D1	D2	D3
	pushbutton	2	1	-	-
	LED	-	-	2	1

Mechanical data					
Weight [g]	100.6				
Type of mounting	AS-i interface to FC and SC lower parts				
Materials	PBT				

Displays / operating elements		
Display	pushbutton	2 x LED, white

Аксессуары	
Items supplied	cover support: 2
	colour inserts: 2, red
	2, green
	2, yellow
	2, blue
	2, white

Remarks	
Remarks	The pushbuttons (EAO type 84) provide protection against accidental contact.
	Housing and pushbuttons can be labelled.
Pack quantity	1 pcs.

Electrical connection	
contact pins to module lower part, FK / PG:	