




AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Article no longer available - archive entry

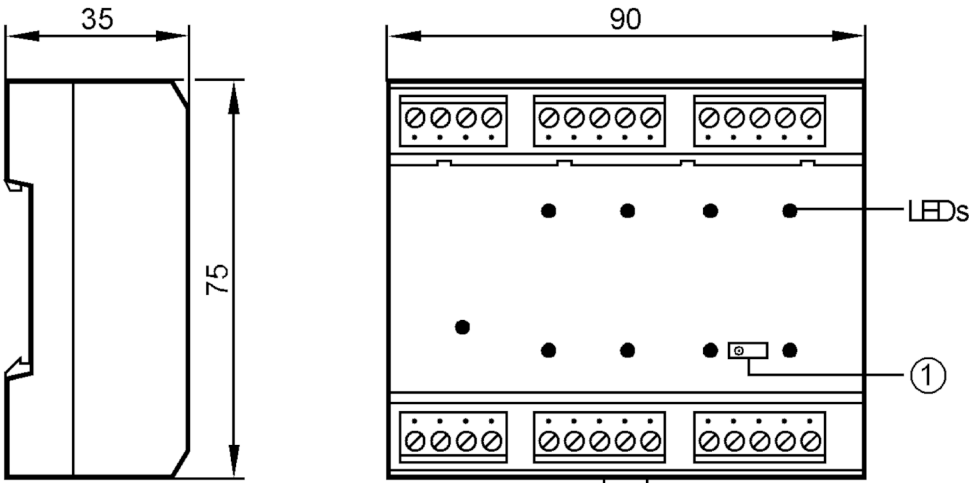

1 addressing socket



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 235
Max. current load total	[A]	4
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs		Number of digital inputs: 4; Number of digital outputs: 4
Inputs		
Number of digital inputs		4; (bidirectional)
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Подача напруги	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	> 5
Input current Low	[mA]	< 1.5
Switching level high	[V]	> 10
Digital inputs protected against short circuits		yes
Outputs		
Electrical design		AS-i
Number of digital outputs		4



AS-Interface control cabinet module

Modul aktiv, 4E 200mA/4AT PNP

Circuit	PNP
Voltage range DC [V]	10...30; (to PELV)
Max. current load per output [mA]	1000
Short-circuit proof	yes
Electrically separated	yes

Operating conditions

Ambient temperature [°C]	-25...80
Protection	IP 00; IP 20

Tests / approvals

EMC	EN 50295
-----	----------

AS-i classification

AS-i profile	S-7.0
AS-i I/O configuration [hex]	7
AS-i ID code [hex]	0
AS-i certificate	05001

Mechanical data

Type of mounting	mounting on DIN rail
Materials	PA; PVC

Displays / operating elements

Display	switching status	LED, yellow
	operation	LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

screw terminals:

Connection

