


AS-Interface repeater

SmartLine25 AS-i Repeater

Article no longer available - archive entry

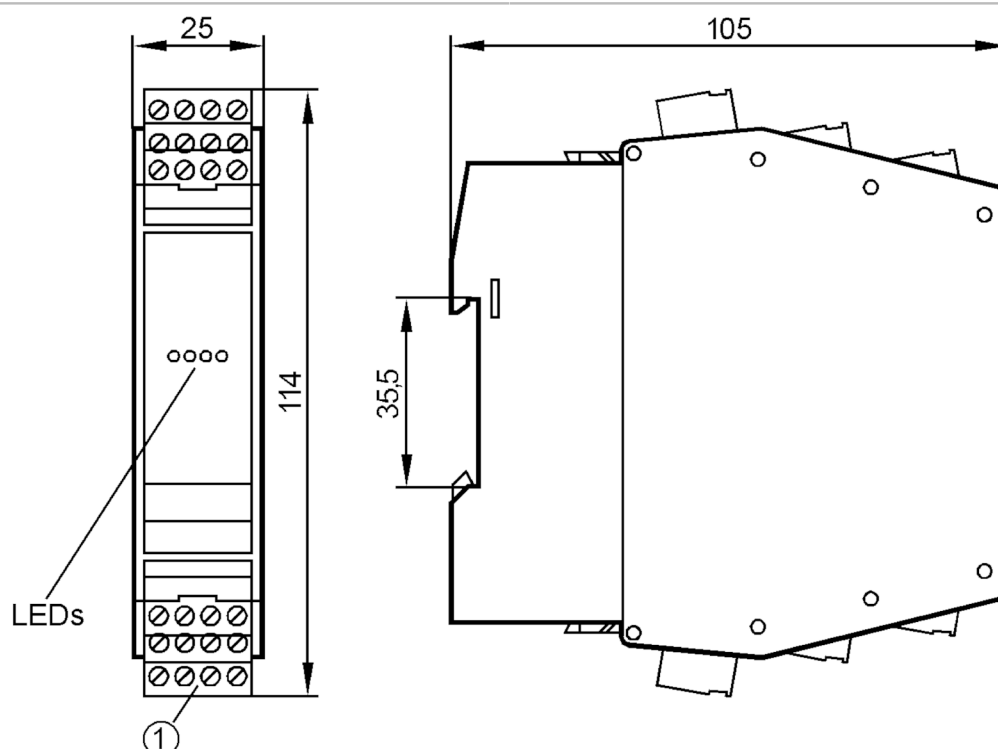

1 COMBICON connector with screw terminals optional



Application

Application	extension of the AS-i network by another 100 m
-------------	--

Electrical data

Nominal voltage DC	[V]	26.5...31.6
Max. current consumption from AS-i	[mA]	2
Undervoltage monitoring		no

Outputs

Electrical design	AS-i
Electrically separated	yes

Operating conditions

Ambient temperature	[°C]	0...55
Protection		IP 20

Tests / approvals

EMC	EN 50295
-----	----------

Mechanical data

Housing	mounting on DIN rail
Materials	PA 6.6

Displays / operating elements

Display	operation	2 x LED, green
	short circuit	2 x LED, red



AS-Interface repeater

SmartLine25 AS-i Repeater

Remarks	
Remarks	The AS-i extender takes no slave address. The total number of slaves per master string remains unchanged. No parameter setting necessary.
Pack quantity	1 pcs.

Electrical connection

Connection	
	
A1+	AS-i + string 1
A1-	AS-i - string 1
A2+	AS-i + string 2
A2-	AS-i - string 2