




AS-Interface control cabinet module

SmartL25 4DO T C

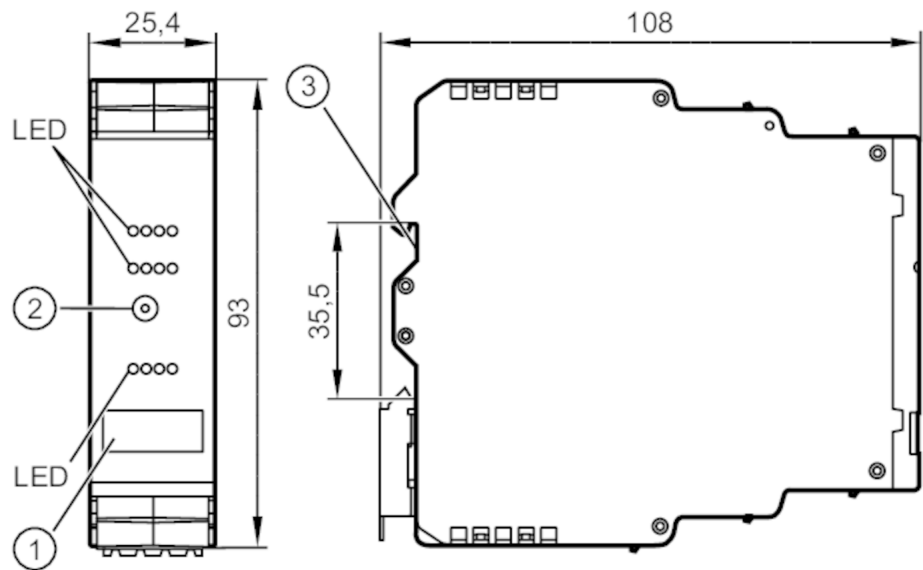

- 1 panel for labelling
- 2 addressing socket
- 3 DIN rail adapter



Application		
Application	Встановлення до шафи керування	
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	50
Additional voltage supply	[V]	20...30 DC; (AUX)
Max. current consumption from additional supply	[mA]	4000; (AUX)
Integrated watchdog		yes
Inputs / outputs		
Number of inputs and outputs	Number of digital outputs: 4	
Outputs		
Number of digital outputs		4
Circuit		PNP
Voltage range DC	[V]	20...30; (AUX)
Max. current load per output	[mA]	1000; (utilisation category DC-12: 700 mA; utilisation category DC-13 (control of electromagnets): 20 W (IEC 60947-5-1))
Max. current load outputs total	[A]	4



AS-Interface control cabinet module

SmartL25 4DO T C

Short-circuit proof	yes
Electrically separated	yes
Actuator supply outputs	AUX

Operating conditions

Ambient temperature [°C]	-25...70
Max. relative air humidity [%]	90; (non condensing)
Max. height above sea level [m]	2000
Protection	IP 20
Pollution degree	2

Tests / approvals

EMC	EN 61000-6-2	
	EN 62026-2	
	EN 50581	
MTTF [ANN]	254	
Notes	The device shall be supplied from an isolating source.; This voltage source must have a secondary UL-listed fuse (see enclosed sheet).; Alternatively, a class 2 power supply can be used to supply AUX.	

AS-i classification

AS-i version	2.11; 3.0				
AS-i addressing	addressing socket				
Розширений режим адресації	no				
AS-i master profile	M2; M3; M4				
AS-i profile	S-8.0.E				
AS-i I/O configuration [hex]	8				
AS-i ID code [hex]	0.E				
AS-i certificate	37302				
Assignment of the data bits	data bit	D0	D1	D2	D3
	Output	O-1	O-2	O-3	O-4

Mechanical data

Weight [g]	126
Type of mounting	mounting on DIN rail
Materials	PC-GF20

Displays / operating elements

Display	switching status	LED, yellow O1...O4
	operation	LED, green AS-i, AUX
	errors	LED, red

Аксессуары

Accessories (optional)	connectors
------------------------	------------

Remarks

Pack quantity	1 pcs.
---------------	--------





AS-Interface control cabinet module

SmartL25 4DO T C

Electrical connection

pin header:

Connection

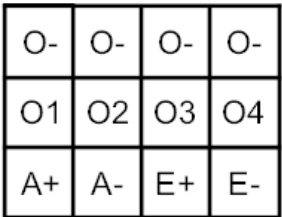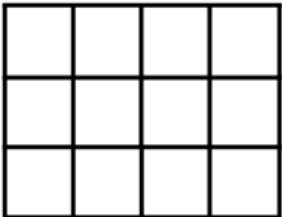

A+	AS-i +
A-	AS-i -
E+	actuator supply +24V
E-	actuator supply 0V
O1...O4	switching output actuator 1...4