


AS-Interface dual sensor for pneumatic valve actuators

DUAL SENSOR T4 2SI M12

Article no longer available - archive entry

Alternative articles: AC2315

When selecting an alternative article and accessories please note that technical data may differ!

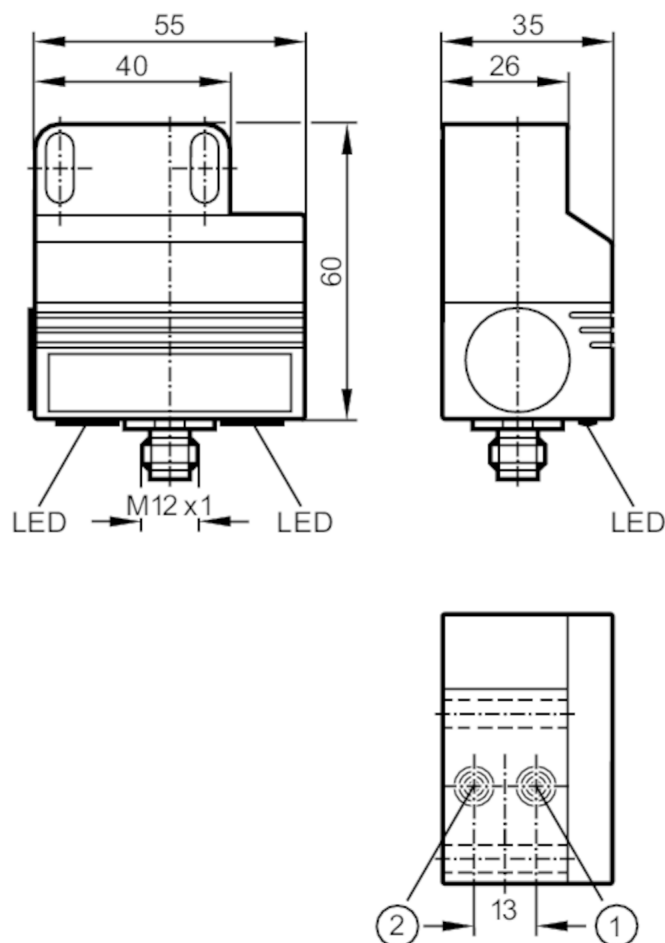

1 sensor 1
2 sensor 2



Product characteristics

Sensing range	[mm]	4
Dimensions	[mm]	55 x 60 x 35

Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Detection zone

Sensing range	[mm]	4
---------------	------	---

Operating conditions

Ambient temperature	[°C]	-20...70
Protection		IP 67

AS-i classification

AS-i I/O configuration	[hex]	7
------------------------	-------	---

AC2305



AS-Interface dual sensor for pneumatic valve actuators

DUAL SENSOR T4 2SI M12

AS-i ID code	[hex]	F
AS-i certificate		15102

Mechanical data

Mounting		non-flush mountable
Dimensions	[mm]	55 x 60 x 35
Materials		PBT

Displays / operating elements


Display	switching status	2 x LED, yellow
---------	------------------	-----------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12; coding: A; Locking: stainless steel (1.4305 / 303)

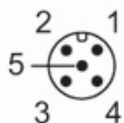

Connection

