

AC315A




AS-Interface dual sensor for pneumatic valve actuators

DUAL SENSOR T4 2SI 3D

Article no longer available - archive entry

Alternative articles: AC336A
When selecting an alternative article and accessories please note that technical data may differ!

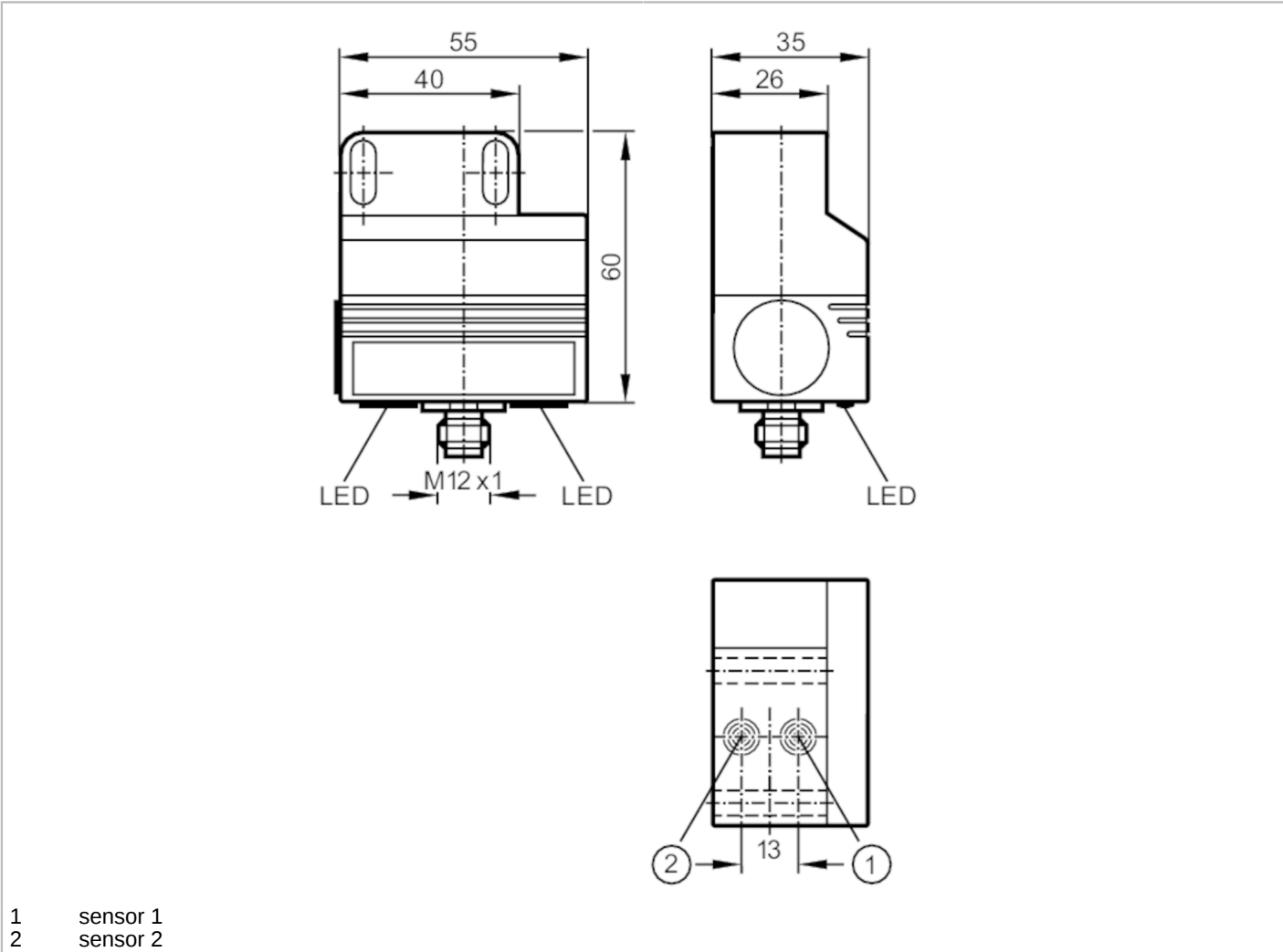

Product characteristics		
Sensing range	[mm]	4
Dimensions	[mm]	55 x 60 x 35
Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 40
Protection class		III
Detection zone		
Sensing range	[mm]	4
Operating conditions		
Ambient temperature	[°C]	-10...60
Protection		IP 5x; (when used outside the hazardous area: IP 67)

AC315A



AS-Interface dual sensor for pneumatic valve actuators

DUAL SENSOR T4 2SI 3D

Tests / approvals		
ATEX marking	II 3D Ex tD A22 IP5X T80°C X Ta: -10...60°C	
Note on ATEX marking	only in conjunction with the mounting plate	
EMC	EN 50295	
AS-i classification		
AS-i version	2.1	
Розширений режим адресації	yes	
AS-i I/O configuration	[hex]	0
AS-i ID code	[hex]	A.F
AS-i certificate	74901	
Mechanical data		
Weight	[g]	163.8
Mounting	non-flush mountable	
Dimensions	[mm]	55 x 60 x 35
Materials	PBT	
Displays / operating elements		
Display	switching status	2 x LED, yellow
Аксессуары		
Items supplied	Mounting plate: 1 socket head screws: 2 x M5 x 35	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - plug		
Connector: 1 x M12; coding: A; Locking: stainless steel (1.4305 / 303)		

AC315A



AS-Interface dual sensor for pneumatic valve actuators

DUAL SENSOR T4 2SI 3D

Connection

