


Lower part for AS-Interface module

EMS-Base FC V2A

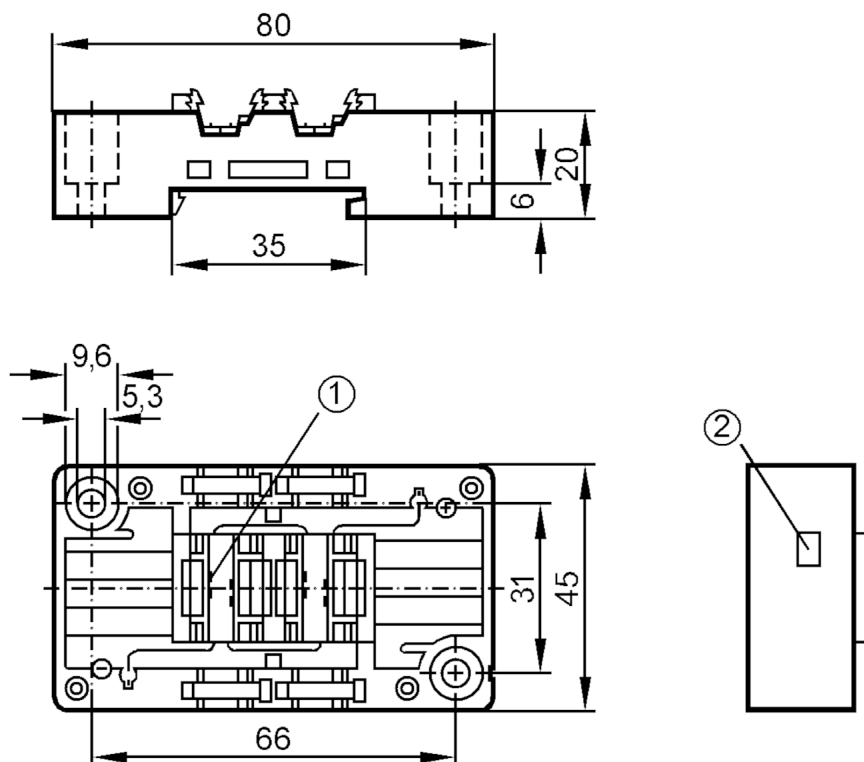

- 1 contact pins
2 panel for labelling



Electrical data

Operating voltage [V] 26.5...31.6 DC

Outputs

Electrical design AS-i
Contact rating < 2 A

Operating conditions

Ambient temperature [°C] -25...85
Protection IP 67; (depending on the upper part used: IP 20 / IP 65 / IP 67)

Mechanical data

Weight [g] 59.7
Type of mounting mounting on DIN rail and panel
Materials PBT; stainless steel (1.4305 / 303)

Remarks

Pack quantity 1 pcs.

Electrical connection

contact pins in module upper part :
quick mounting technology for AS-i flat cable: