


Lower part for AS-Interface module

EMS-BASE RC ST SET

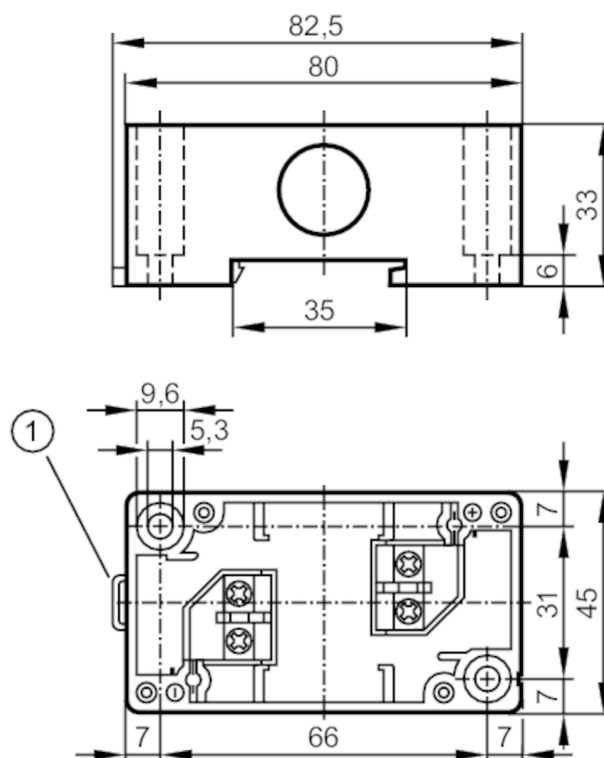

1 locking bolt

Electrical data

Operating voltage	[V]	26.5...31.6 DC
-------------------	-----	----------------

Outputs

Electrical design	AS-i
Contact rating	< 4 A

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 65

Mechanical data

Weight	[g]	115.2
Type of mounting		mounting on DIN rail and panel
Materials		PBT

Аксессуары

Items supplied	flat cable seals: 2, NBR кабельні вводи: 3 захисні заглушки: 3 hexagon nuts: 4
Accessories (optional)	cover:, for AS-i module, AC3000 screw terminal insert:, AC5007

Remarks

Remarks	up to 4 M20 cable ports for any T and cross branches
Pack quantity	1 pcs.

AC5031



Lower part for AS-Interface module

EMS-BASE RC ST SET

Electrical connection

screw terminals: ...2.5 mm²