




AS-Interface ClassicLine module with quick mounting technology

ClassicLine 4SB IP67

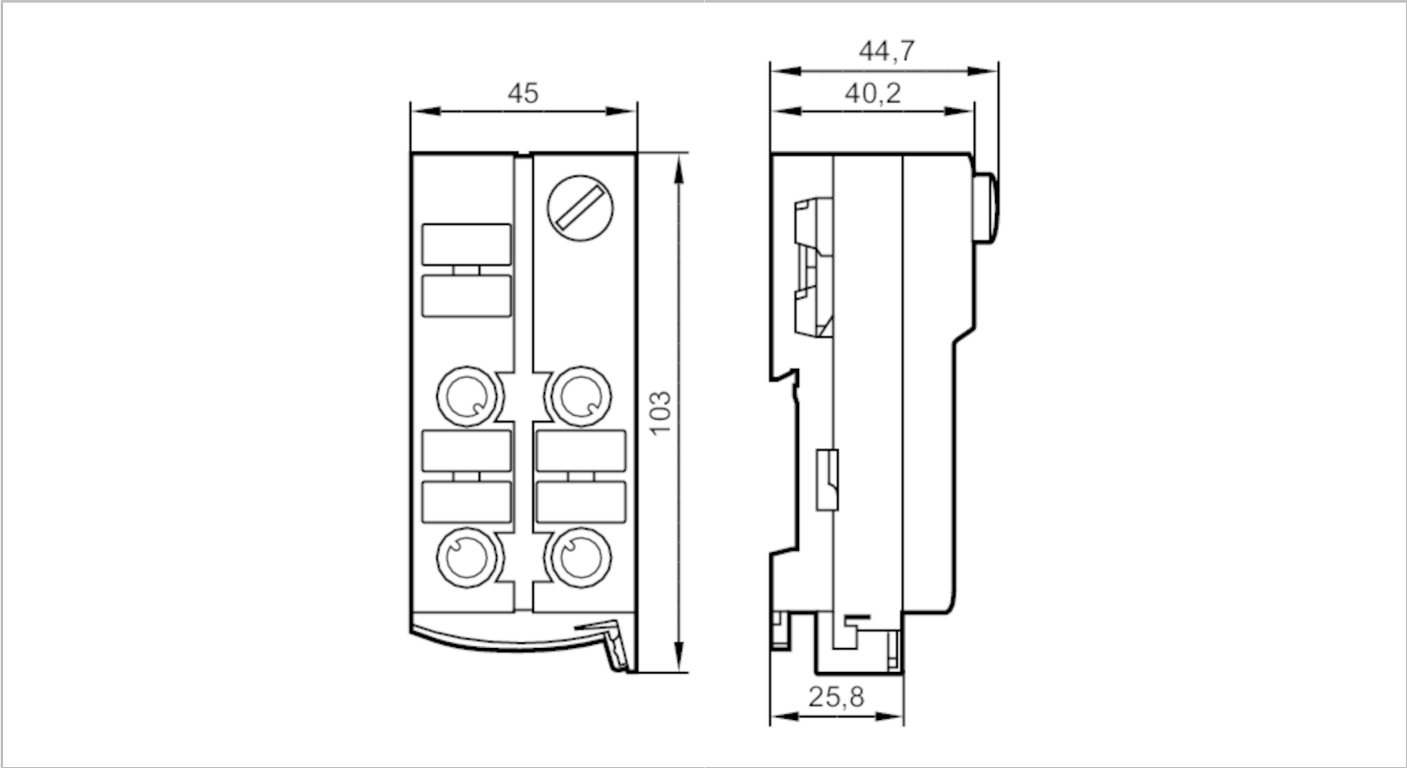

Application		
Application	field installation	
Electrical data		
Operating voltage	[V]	26.5...31.6 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	2; (AS-i: 2; AUX: 2)
Additional voltage supply	[V]	15...30 DC; (AUX ; "supply class 2" to cULus)
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Tests / approvals		
EMC	EN 50295	
	IEC 61000-6-2	
MTTF	[ANN]	10284
Mechanical data		
Weight	[g]	152.5
Type of mounting		AS-i flat cables directly connectable
Dimensions	[mm]	103 x 45 x 44.7
Materials		PA; piercing contacts: CuSn6 nickel-plated and tin-plated
Electrical connection		
Module connection		Приладдя
Аксессуары		
Items supplied		lower part



AS-Interface ClassicLine module with quick mounting technology

ClassicLine 4SB IP67	
Accessories (optional)	Protective cap: M12, E73004


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

quick mounting technology for AS-i flat cable: ; three orientations possible

Connector: M12; coding: A

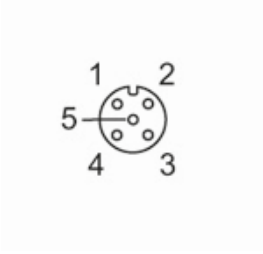

1	AS-i +
2	external voltage -
3	AS-i -
4	external voltage +