


DF2212



Electronic circuit breaker

Fuse/IO-Link/24VDC/2x2A

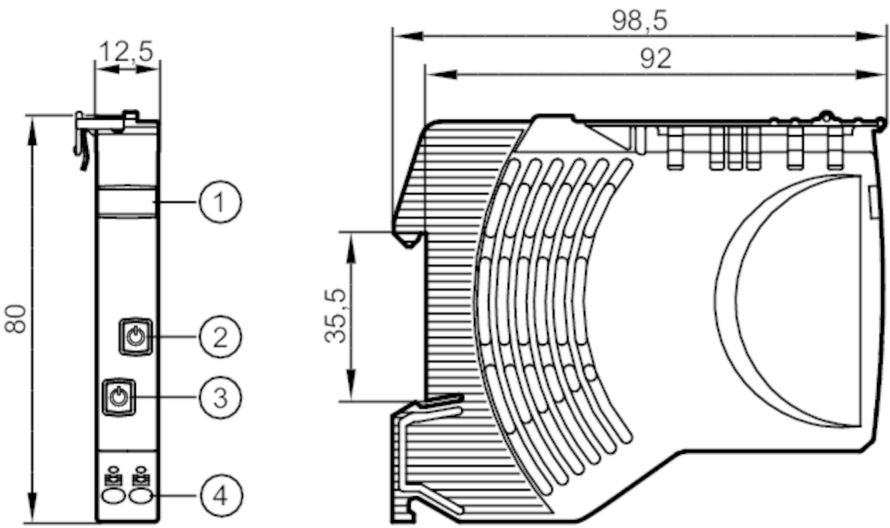

- 1 panel for labelling
- 2 pushbutton on / off / reset status LED 2
- 3 pushbutton on / off / reset status LED 1
- 4 push-in terminals Outputs 1/2



Electrical data		
Operating voltage	[V]	to SELV/PELV ; "клас живлення 2" згідно з UR
Nominal voltage DC	[V]	24
Input voltage DC	[V]	19.2...30
Protection class		III
Mains buffering time (nominal voltage 24 V DC)	[ms]	10
Closed-circuit current	[mA]	8
Number of channels		2
Nominal current	[A]	2
Nominal current (Fail Safe Element)	[A]	2
Outputs		
Load capacitance, total	[mF]	10
Operating conditions		
Ambient temperature	[°C]	-25...60
Storage temperature	[°C]	-40...70
Protection		IP 20; (on the front)
Pollution degree		2
Tests / approvals		
EMC	EN 61000-6-3	radiation of interference
	EN 61000-6-2	immunity
Mechanical data		
Weight	[g]	72.5

DF2212



Electronic circuit breaker

Fuse/IO-Link/24VDC/2x2A

Dimensions	[mm]	80 x 12.5 x 98.5
------------	------	------------------

Displays / operating elements


Display	status	2 x LED, red / green / orange
Operating elements	2 x	pushbutton

Electrical connection

push-in terminals:


contact lever/strip:

Connection

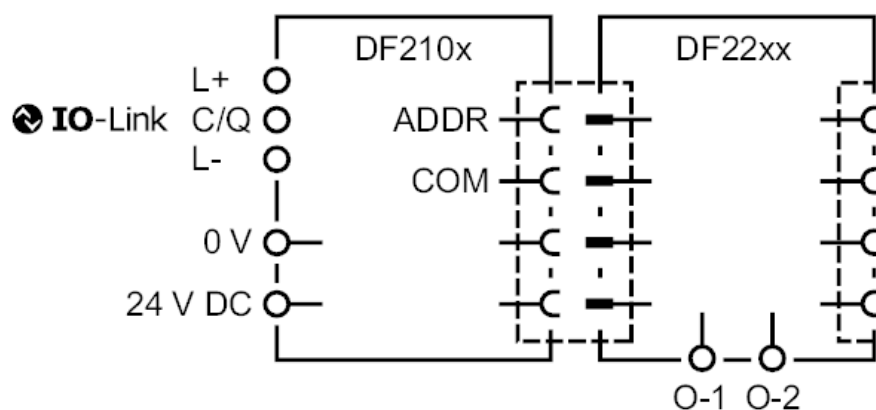

Diagrams and graphs

output characteristics

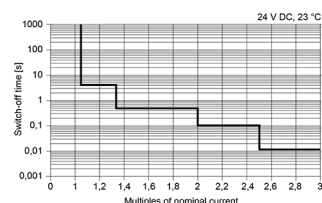

time-current characteristics