


# DF3200



## Distribution module for supply voltage

Pot.Module LOAD/2x5x 2.5mm<sup>2</sup>

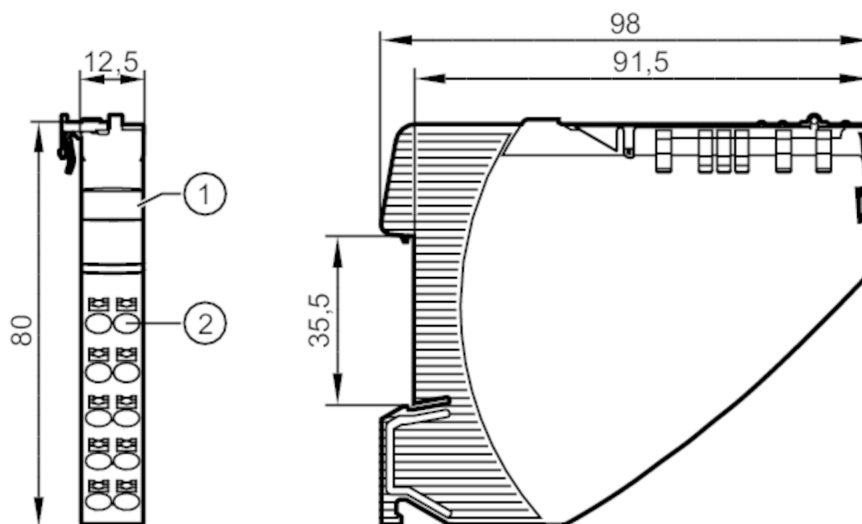

- 1 panel for labelling  
2 push-in terminal 24 V DC



### Application

Design potential module 2 x 5 x 2,5 mm<sup>2</sup>

### Electrical data

|                        |            |
|------------------------|------------|
| Operating voltage [V]  | 18...30 DC |
| Nominal voltage DC [V] | 24         |
| Protection class       | III        |
| Max. load current [A]  | 20         |

### Operating conditions

|                          |          |
|--------------------------|----------|
| Ambient temperature [°C] | -25...60 |
| Storage temperature [°C] | -40...70 |
| Protection               | IP 20    |

### Tests / approvals

|     |              |                           |
|-----|--------------|---------------------------|
| EMC | EN 61000-6-3 | radiation of interference |
|     | EN 61000-6-2 | immunity                  |

### Mechanical data

|                          |                          |
|--------------------------|--------------------------|
| Weight [g]               | 64.8                     |
| Type of mounting         | mounting on DIN rail     |
| Installation instruction | string mounting possible |
| Dimensions [mm]          | 80 x 12.5 x 98.5         |

# DF3200



## Distribution module for supply voltage

Pot.Module LOAD/2x5x 2.5mm<sup>2</sup>

### Electrical connection

push-in terminals:

#### Connection

