

# DN0501




## Switching amplifier

N605/230VAC/0,8A

Article no longer available - archive entry

Alternative articles: DN1020

When selecting an alternative article and accessories please note that technical data may differ!

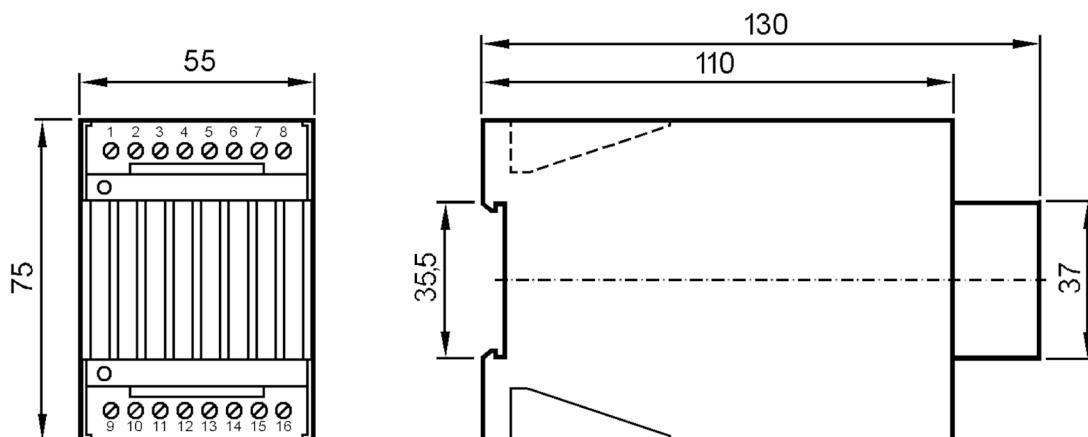

### Electrical data

|                                            |      |         |
|--------------------------------------------|------|---------|
| Nominal frequency AC                       | [Hz] | 47...63 |
| Output voltage                             | [V]  | set     |
| Output voltage tolerance                   | [%]  | 5       |
| Max. output current at min. output voltage | [A]  | 0.8     |
| Number of output circuits                  |      | 1       |

### Outputs

|                          |     |
|--------------------------|-----|
| Short-circuit protection | yes |
| Overload protection      | yes |

### Operating conditions

|                     |      |        |
|---------------------|------|--------|
| Ambient temperature | [°C] | 0...50 |
| Protection          |      | IP 40  |

### Mechanical data

|           |          |
|-----------|----------|
| Materials | plastics |
|-----------|----------|

### Displays / operating elements

|         |                |                |
|---------|----------------|----------------|
| Display | Output voltage | 2 x LED, green |
|---------|----------------|----------------|

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# DN0501



## Switching amplifier

N605/230VAC/0,8A

### Electrical connection

terminals: ...4 mm<sup>2</sup>

### Connection

