


DN1030



Switched-mode power supply 24 V DC

PSU-1AC/24VDC-1,3A

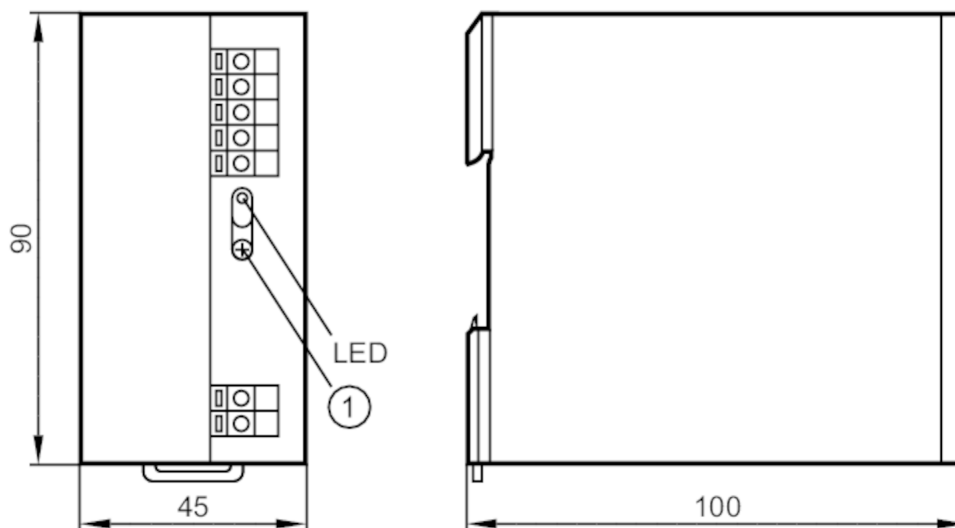

1 potentiometer



Electrical data

Operating voltage tolerance	[%]	10
Nominal voltage AC	[V]	< 230
Nominal frequency AC	[Hz]	47...63
Input voltage range AC	[V]	100...240
Output voltage DC	[V]	24...28
Protection class		II; (IEC 61140)
Power-on delay time	[s]	< 0.255
Output voltage	[V]	adjustable
Max. output current at min. output voltage	[A]	1.25
Number of output circuits		1
Max. residual ripple	[mV]	50
Efficiency (nominal voltage 230 V AC / 50 Hz)	[%]	84
External input protection		10 A; B
Derating	[W/K]	2% / K (> 60° C)
Mains buffering time (nominal voltage 230 V AC / 50 Hz)	[ms]	120

Outputs

Short-circuit proof	yes
Overload protection	yes
Reliability of the DC OK signal	24 V DC (30 mA)

Operating conditions

Ambient temperature	[°C]	0...70
Protection		IP 20

DN1030



Switched-mode power supply 24 V DC

PSU-1AC/24VDC-1,3A

Tests / approvals

EMC	EN 61000-6-2	
	EN 61000-6-3	

Mechanical data

Weight	[g]	278.5
Type of mounting		rail; (TH35 (EN 60715); free space for convection cooling 30 mm)
Dimensions	[mm]	90 x 45 x 100
Materials		PC ABS

Displays / operating elements

Display	DC ok	1 x LED, green
---------	-------	----------------


Remarks

Remarks	output voltage to SELV, PELV	
Pack quantity	1 pcs.	

Electrical connection

cage clamps:

Connection

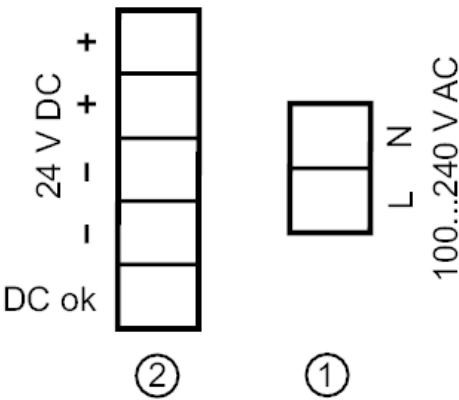

- 1: primary
2: secondary