


DP3222



Converter 0...10 V - IO-Link

CONV 2x0-10V/IO-LINK/IP69K

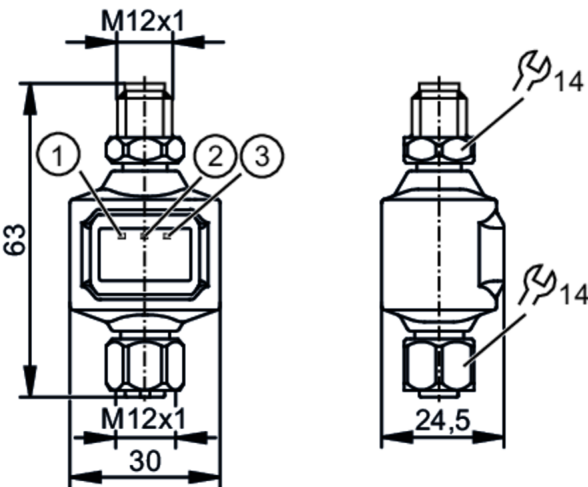

- 1 LED I
- 2 Power
- 3 LED II



Product characteristics

Number of inputs and outputs	Number of analogue inputs: 2
Communication interface	IO-Link

Application

Application	конвертер з аналогових сигналів напруги в IO-Link; для підключення аналогових датчиків до IO-Link системи; для використання у вологому середовищі; використання в приміщенні
-------------	--

Electrical data

Operating voltage [V]	18...30 DC; ((у вологому середовищі: 18...28 V) to SELV/PELV)
Nominal voltage DC [V]	24
Current consumption [mA]	300

Inputs / outputs

Number of inputs and outputs	Number of analogue inputs: 2
------------------------------	------------------------------

Inputs

Max. total current rating of inputs [mA]	200
Number of analogue inputs	2
Analogue input (voltage) [V]	0...10

Interfaces

Communication interface	IO-Link
Transmission type	COM2 (38,4 kBaud)
IO-Link revision	1.1
SDCI standard	IEC 61131-9
Profiles	Smart Sensor 0x4000: Identification and Diagnosis 0x8001: Switching Signal Channel 0x8006: Adjustable Switching Signal Channel
SIO mode	no
Required master port type	A/B

DP3222



Converter 0...10 V - IO-Link

CONV 2x0-10V/IO-LINK/IP69K

Process data analogue	2	
Supported DeviceIDs	Type of operation	DeviceID
	STATUS_B / CMPT = 2 (Factory setting)	1428
DP3222 / CMPT = 1		
Min. process cycle time	[ms]	4.3
DP3222 STATUS_B / CMPT = 2 (Factory setting)		
Min. process cycle time	[ms]	4.6
Operating conditions		
Ambient temperature	[°C]	-25...70
Note on ambient temperature		2000 m: -25...70 °C
		3000 m: -25...64 °C
		4000 m: -25...62 °C
Storage temperature	[°C]	-25...70
Max. relative air humidity	[%]	90; (linearly decreasing to 50 % (40 °C) non condensing)
Max. height above sea level	[m]	4000
Protection		IP 67; IP 69K
Pollution degree		2
Tests / approvals		
MTTF	[ANN]	504
Mechanical data		
Weight	[g]	78.6
Weight (without accessories and packaging)	[g]	27
Dimensions	[mm]	63 x 30 x 24.5
Materials		housing: PA
Material nut		stainless steel (1.4404 / 316L)
Sealing material		FKM
Displays / operating elements		
Display	operation	1 x LED, green
	analogue input	2 x LED, yellow
Remarks		
Remarks	For further information please see the operating instructions.	
Pack quantity	1 pcs.	

DP3222



Converter 0...10 V - IO-Link

CONV 2x0-10V/IO-LINK/IP69K

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Locking: stainless steel (1.4404 / 316L)



- | | |
|----|-------------------|
| 1: | L+ supply voltage |
| 2: | not used |
| 3: | L- supply voltage |
| 4: | C/Q IO-Link |

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Locking: stainless steel (1.4404 / 316L); Sealing: FKM

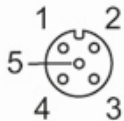

- | | |
|----|---------------------------|
| 1: | L+ |
| 2: | 0...10 V analogue input 2 |
| 3: | L- |
| 4: | 0...10 V analogue input 1 |
| 5: | not used |