

DTMHF INRWCOUS03



DTM435



RFID read/write head with CAN interface and CANopen protocol

DTMHF INRWCOUS03


Mechanical data		
Weight	[g]	175.15
Housing		threaded type
Dimensions	[mm]	M30 x 1.5 / L = 70
Thread designation		M30 x 1.5
Materials		housing: stainless steel; Protective cover: PPS; LED window: PEI

Displays / operating elements		
Display	Preoperational Mode	1 x LED, green lights
	Operational Mode	1 x LED, green flashing
	errors	1 x LED, red flashing
	tag communication	1 x LED, yellow lights

Remarks	
Pack quantity	1 pcs.

Electrical connection

Connector: 1 x M12; coding: A

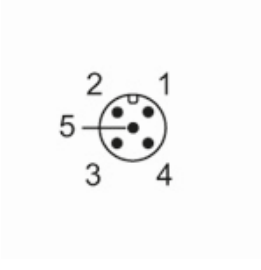

1	not used
2	U+
3	GND
4	CAN_H
5	CAN_L