


DX2031



Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/DC

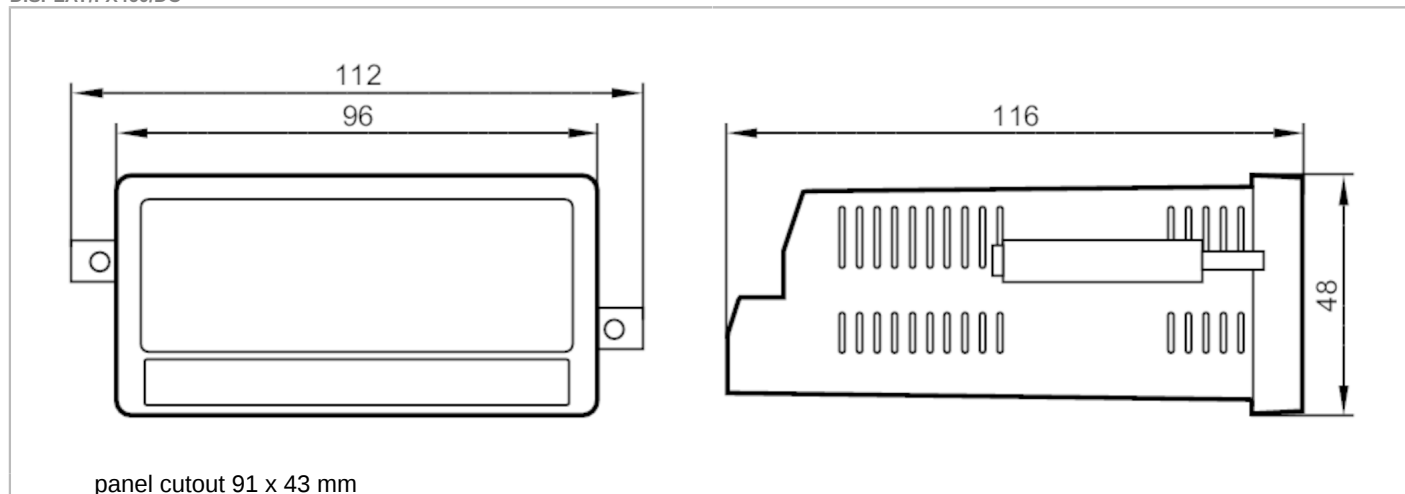

Product characteristics		
Dimensions	[mm]	48 x 112 x 116
Application		
Application	universal evaluation and display for all physical units which can be derived from pulse sequences	
Electrical data		
Operating voltage	[V]	18...30 DC
Current consumption	[mA]	100
Inputs / outputs		
Number of inputs and outputs	Number of digital inputs: 2	
Inputs		
Number of digital inputs	2	
Operating conditions		
Ambient temperature	[°C]	-20...60
Storage temperature	[°C]	-25...70
Protection	IP 65	
Protection rating terminals	IP 20	
Tests / approvals		
EMC	EN 61000-6-2	
	EN 61000-6-3	
	EN 61000-6-4	
Mechanical data		
Weight	[g]	302.5
Type of mounting	panel cutout: 91 x 43 mm	
Dimensions	[mm]	48 x 112 x 116
Materials	Noryl UL94-V-0	
Displays / operating elements		
Display	colour display	full graphic LCD display, touch screen

DX2031




Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/DC

Electrical connection

screw terminals:

Connection

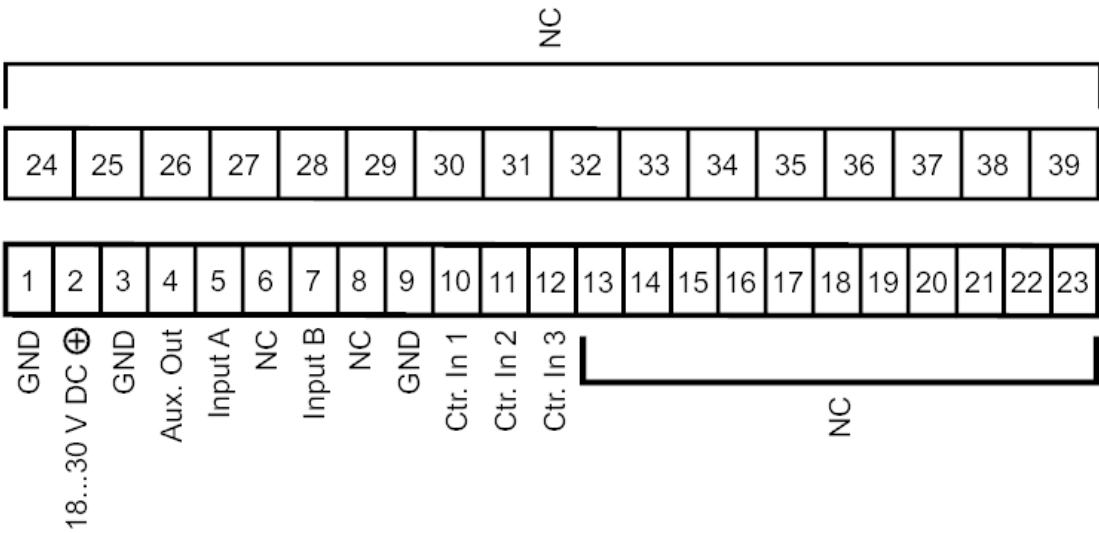

NC: not used