


E3M122



Connection cable

MCI CONNECTION CABLE 2M

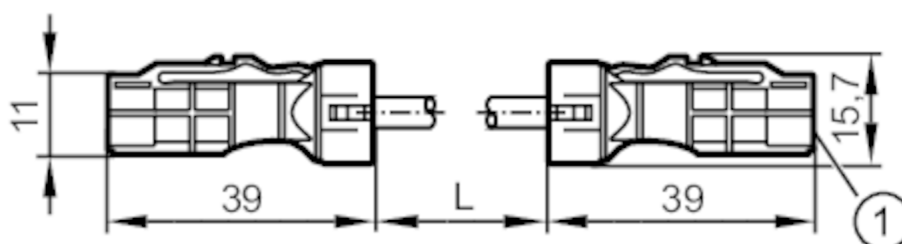

1 MCI



Application		
Special feature		Drag chain suitability
Electrical data		
Operating voltage	[V]	< 25 AC / < 60 DC
Operating conditions		
Ambient temperature	[°C]	-40...105
Protection		IP 67
Mechanical data		
Weight	[g]	89.15
Drag chain suitability		yes
Drag chain suitability	bending radius for fixed installation	≥ 40 mm
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 2 m, TPU, black		