


E3M161



Connection cable

VIDEO ADAPTER CABLE M12 M16

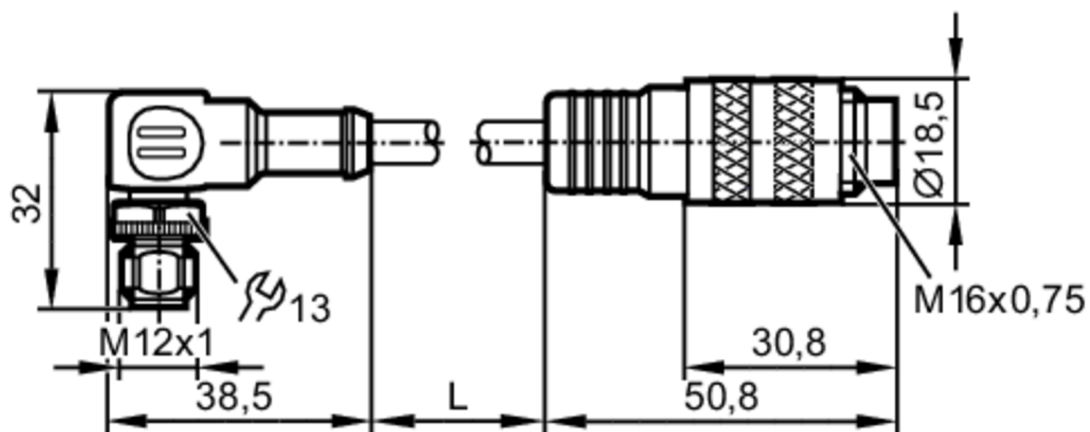

Application

Special feature	Screened cable; Drag chain suitability
Design	for 3D Smart sensor mobile with analogue video output PAL

Electrical data

Operating voltage	[V]	< 25 AC / < 60 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-40...80
Ambient temperature (moving)	[°C]	-10...70
Protection		IP 67; IP 69K

Mechanical data

Weight	[g]	92.2
Materials		PUR black; sealing ring: FKM; contact pins: CuSn6 nickel-plated and tin-plated
Moulded-body material		PUR
Material nut		stainless steel (1.4305 / 303)
Drag chain suitability		yes
Drag chain suitability	bending radius for fixed installation	≥ 60 mm

Remarks

Pack quantity	1 pcs.
---------------	--------

E3M161




Connection cable

VIDEO ADAPTER CABLE M12 M16

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303); Shielded connection cable: screen connected

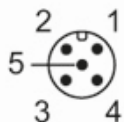

Electrical connection

Cable: 1 m, PUR, black, Ø 6 mm, shielded; 2 x 0.25 mm²

Connection

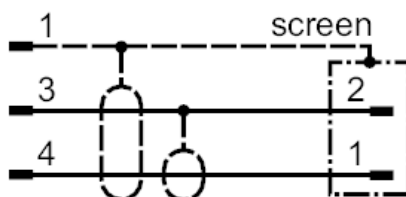

Electrical connection - plug

Connector: 1 x M16, straight; coding: A; Moulded body: PUR; Locking: stainless steel (1.4305 / 303); Shielded connection cable: screen connected

