

E10433



Connecting cable with socket

ADOAH042VAS0010E03

Article no longer available - archive entry



Electrical data

Operating voltage [V] 10...30 DC

Outputs

Electrical design PNP

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU transparent

Moulded-body material TPU, transparent

Material nut stainless steel (1.4404 / 316L)

Remarks

Pack quantity 1 pcs.

E10433



Connecting cable with socket

ADOAH042VAS0010E03

Electrical connection


Cable: 10 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.5 Nm



Connection

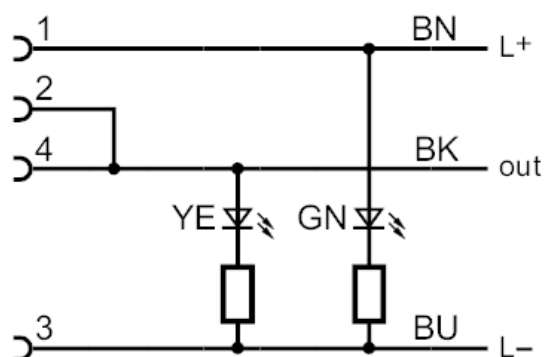

BK = black
BN = brown
BU = blue

Core colours :