




Adapter plug

ESTGH020MSS0,05E02 (PG13,5)

Article no longer available - archive entry

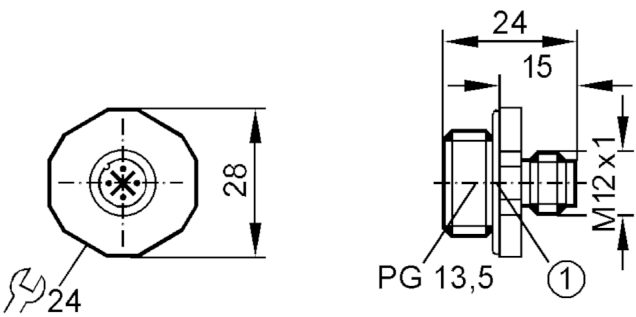

1 O-ring

Electrical data

Operating voltage [V] < 55 DC

Operating conditions

Ambient temperature [°C] -40...85

Protection IP 67

Mechanical data

Mounting thread PG 13.5

Materials brass nickel-plated

Moulded-body material brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 0.05 m, PVC; 2 x 0.34 mm<sup>2</sup>

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



# E10436



## Adapter plug

ESTGH020MSS0,05E02 (PG13,5)

### Connection

1 BK

4 WH

BK = Core colours :  
WH = black  
white