

E10445




Splitter box

ZDO6H057MSS0000-00STAM120MSS

Article no longer available - archive entry

Alternative articles: EBC006
When selecting an alternative article and accessories please note that technical data may differ!

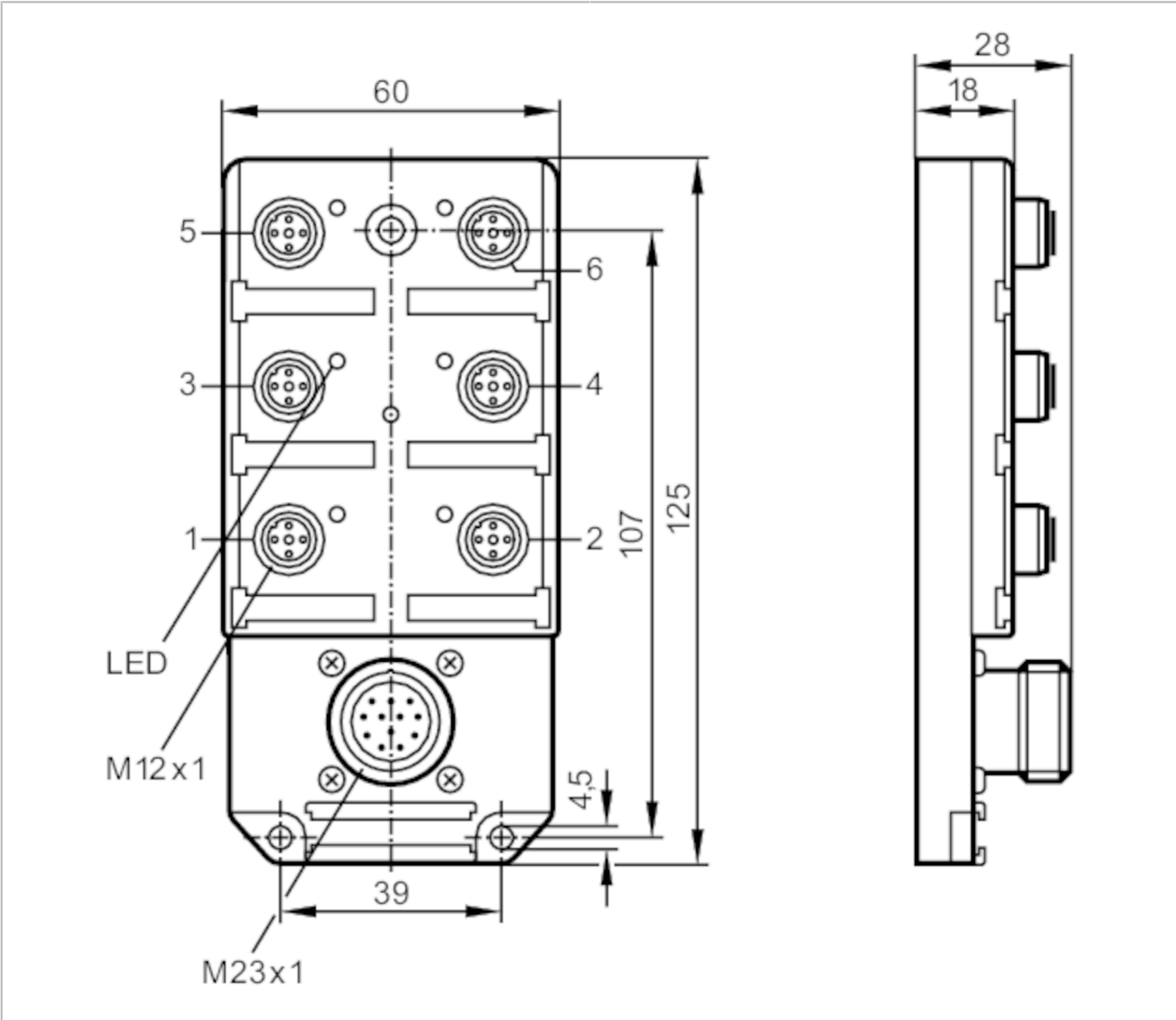

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12



Splitter box

ZDO6H057MSS0000-00STAM120MSS

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Number of ports splitter box	6
Connector type	M12

Displays / operating elements


Display	switching status	6 x LED, yellow
	operation	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

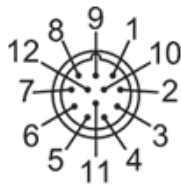

Connection

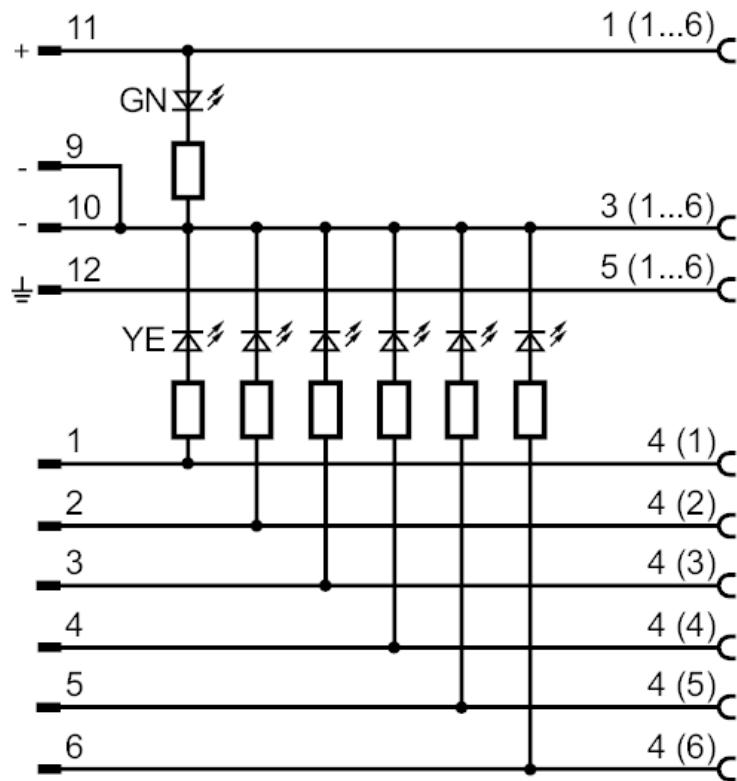

E10445



Splitter box

ZDO6H057MSS0000-00STAM120MSS

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

