

E10460



Connection cable

VDOGH042MSS01,5A04STGH040MSS

Article no longer available - archive entry



Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Displays / operating elements


Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

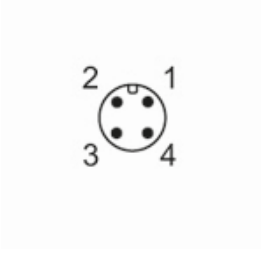

E10460



Connection cable

VDOGH042MSS01,5A04STGH040MSS

Electrical connection

Cable: 1.5 m, PUR / PVC; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection



Core colours :
BK = black
BN = brown
BU = blue
WH = white

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

